

Cylindrical spacer




PLB

Brass

- Machined pillar
- Material:
Brass
- Sold by the packet

Option

- Alternative lengths are available

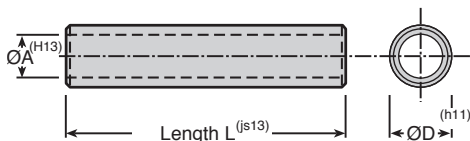

DISCOUNTS

No pack Disc	1+	5+	20+	100+
	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB2-1/B	2,0	2,2	4	1	20	✓	2,81 €
PLB2-2/B	2,0	2,2	4	2	20	✓	2,90 €
PLB2-3/B	2,0	2,2	4	3	20	-	3,02 €
PLB2-4/B	2,0	2,2	4	4	20	✓	3,17 €
PLB2-5/B	2,0	2,2	4	5	20	✓	3,25 €
PLB2-8/B	2,0	2,2	4	8	20	✓	3,43 €
PLB2-10/B	2,0	2,2	4	10	20	-	3,70 €
PLB2-12/B	2,0	2,2	4	12	20	-	3,81 €
PLB2.5-1/B	2,5	2,5	5	1	20	-	2,90 €
PLB2.5-2/B	2,5	2,5	5	2	20	-	3,02 €
PLB2.5-3/B	2,5	2,5	5	3	20	✓	3,17 €
PLB2.5-4/B	2,5	2,5	5	4	20	✓	3,28 €
PLB2.5-5/B	2,5	2,5	5	5	20	✓	3,43 €
PLB2.5-8/B	2,5	2,5	5	8	20	✓	3,81 €
PLB2.5-10/B	2,5	2,5	5	10	20	-	4,05 €
PLB2.5-12/B	2,5	2,5	5	12	20	-	4,34 €
PLB2.5-20/B	2,5	2,5	5	20	20	✓	6,30 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB3-2/B	3,0	3,2	6	2	20	✓	2,81 €
PLB3-3/B	3,0	3,2	6	3	20	✓	3,02 €
PLB3-4/B	3,0	3,2	6	4	20	✓	3,17 €
PLB3-5/B	3,0	3,2	6	5	20	✓	3,28 €
PLB3-8/B	3,0	3,2	6	8	20	✓	3,81 €
PLB3-10/B	3,0	3,2	6	10	20	✓	4,20 €
PLB3-12/B	3,0	3,2	6	12	20	✓	4,59 €
PLB3-15/B	3,0	3,2	6	15	20	✓	5,12 €
PLB3-20/B	3,0	3,2	6	20	20	-	6,21 €
PLB3-25/B	3,0	3,2	6	25	20	-	8,02 €
PLB3-30/B	3,0	3,2	6	30	20	-	9,49 €
PLB4-2/B	4,0	4,3	8	2	20	✓	3,02 €
PLB4-3/B	4,0	4,3	8	3	20	✓	3,28 €
PLB4-4/B	4,0	4,3	8	4	20	✓	3,54 €
PLB4-5/B	4,0	4,3	8	5	20	✓	3,70 €
PLB4-8/B	4,0	4,3	8	8	20	✓	4,59 €
PLB4-10/B	4,0	4,3	8	10	20	✓	5,25 €
PLB4-12/B	4,0	4,3	8	12	20	✓	6,04 €
PLB4-15/B	4,0	4,3	8	15	20	✓	6,84 €
PLB4-18/B	4,0	4,3	8	18	20	-	7,62 €
PLB4-20/B	4,0	4,3	8	20	20	✓	8,40 €
PLB4-25/B	4,0	4,3	8	25	20	-	10,92 €
PLB4-30/B	4,0	4,3	8	30	20	✓	12,72 €
PLB5-2/B	5,0	5,3	10	2	20	-	3,81 €
PLB5-3/B	5,0	5,3	10	3	20	✓	4,20 €
PLB5-4/B	5,0	5,3	10	4	20	✓	4,59 €
PLB5-5/B	5,0	5,3	10	5	20	✓	4,98 €
PLB5-8/B	5,0	5,3	10	8	20	✓	7,25 €
PLB5-10/B	5,0	5,3	10	10	20	✓	8,14 €
PLB5-12/B	5,0	5,3	10	12	20	✓	8,68 €
PLB5-15/B	5,0	5,3	10	15	20	✓	10,13 €
PLB5-20/B	5,0	5,3	10	20	20	✓	12,72 €
PLB5-25/B	5,0	5,3	10	25	20	✓	15,40 €
PLB5-30/B	5,0	5,3	10	30	20	✓	18,70 €
PLB5-35/B	5,0	5,3	10	35	20	✓	21,95 €

*Depending on availability - Dimensions in mm

Our other products

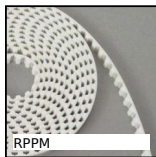

RPPM
RPP type belt per metre, RPP5 Steel cored polyurethane



PRF_ECL
Nut for aluminium profile, Steel square nut with tab



TB8
Cylindrical roller thrust bearing, Steel



TRM
Spur round rack, Steel - module 1-6



M1
Worm and wheel set, Bronze



FBL6000_K1
Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide 6 -...



ZDB
Machined plastic bevel gear, 2:1



PSG05S
Spur gear - precision range, Stainless steel 303



CHA_GC_9SS
Stainless steel garnet hinge, To be welded



NTM
Nylon tipped set screw, Nylon-point



PTAF100-PAMF100
Articulated fixable foot with pressed base Ø100, Ø 100



MC
Self-compensating shock-absorber, Self-compensating - without adjust...

Complementary products



PLN
Cylindrical spacer, Thermoplastic



PLS
Cylindrical spacer, Stainless steel 303