

Cylindrical spacer




PLB

Brass

- Machined pillar
- Material:
Brass
- Sold by the packet

Option

- Alternative lengths are available

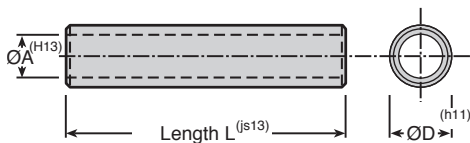

DISCOUNTS

No pack Disc	1+	5+	20+	100+
	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB2-1/B	2,0	2,2	4	1	20	✓	2,81 €
PLB2-2/B	2,0	2,2	4	2	20	✓	2,90 €
PLB2-3/B	2,0	2,2	4	3	20	-	3,02 €
PLB2-4/B	2,0	2,2	4	4	20	✓	3,17 €
PLB2-5/B	2,0	2,2	4	5	20	✓	3,25 €
PLB2-8/B	2,0	2,2	4	8	20	✓	3,43 €
PLB2-10/B	2,0	2,2	4	10	20	-	3,70 €
PLB2-12/B	2,0	2,2	4	12	20	-	3,81 €
PLB2.5-1/B	2,5	2,5	5	1	20	-	2,90 €
PLB2.5-2/B	2,5	2,5	5	2	20	-	3,02 €
PLB2.5-3/B	2,5	2,5	5	3	20	✓	3,17 €
PLB2.5-4/B	2,5	2,5	5	4	20	✓	3,28 €
PLB2.5-5/B	2,5	2,5	5	5	20	✓	3,43 €
PLB2.5-8/B	2,5	2,5	5	8	20	✓	3,81 €
PLB2.5-10/B	2,5	2,5	5	10	20	-	4,05 €
PLB2.5-12/B	2,5	2,5	5	12	20	-	4,34 €
PLB2.5-20/B	2,5	2,5	5	20	20	✓	6,30 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000

Service 0,15 €/min + prix appel

DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB3-2/B	3,0	3,2	6	2	20	✓	2,81 €
PLB3-3/B	3,0	3,2	6	3	20	✓	3,02 €
PLB3-4/B	3,0	3,2	6	4	20	✓	3,17 €
PLB3-5/B	3,0	3,2	6	5	20	✓	3,28 €
PLB3-8/B	3,0	3,2	6	8	20	✓	3,81 €
PLB3-10/B	3,0	3,2	6	10	20	✓	4,20 €
PLB3-12/B	3,0	3,2	6	12	20	✓	4,59 €
PLB3-15/B	3,0	3,2	6	15	20	✓	5,12 €
PLB3-20/B	3,0	3,2	6	20	20	-	6,21 €
PLB3-25/B	3,0	3,2	6	25	20	-	8,02 €
PLB3-30/B	3,0	3,2	6	30	20	-	9,49 €
PLB4-2/B	4,0	4,3	8	2	20	✓	3,02 €
PLB4-3/B	4,0	4,3	8	3	20	✓	3,28 €
PLB4-4/B	4,0	4,3	8	4	20	✓	3,54 €
PLB4-5/B	4,0	4,3	8	5	20	✓	3,70 €
PLB4-8/B	4,0	4,3	8	8	20	✓	4,59 €
PLB4-10/B	4,0	4,3	8	10	20	✓	5,25 €
PLB4-12/B	4,0	4,3	8	12	20	✓	6,04 €
PLB4-15/B	4,0	4,3	8	15	20	✓	6,84 €
PLB4-18/B	4,0	4,3	8	18	20	-	7,62 €
PLB4-20/B	4,0	4,3	8	20	20	✓	8,40 €
PLB4-25/B	4,0	4,3	8	25	20	-	10,92 €
PLB4-30/B	4,0	4,3	8	30	20	✓	12,72 €
PLB5-2/B	5,0	5,3	10	2	20	-	3,81 €
PLB5-3/B	5,0	5,3	10	3	20	✓	4,20 €
PLB5-4/B	5,0	5,3	10	4	20	✓	4,59 €
PLB5-5/B	5,0	5,3	10	5	20	✓	4,98 €
PLB5-8/B	5,0	5,3	10	8	20	✓	7,25 €
PLB5-10/B	5,0	5,3	10	10	20	✓	8,14 €
PLB5-12/B	5,0	5,3	10	12	20	✓	8,68 €
PLB5-15/B	5,0	5,3	10	15	20	✓	10,13 €
PLB5-20/B	5,0	5,3	10	20	20	✓	12,72 €
PLB5-25/B	5,0	5,3	10	25	20	✓	15,40 €
PLB5-30/B	5,0	5,3	10	30	20	✓	18,70 €
PLB5-35/B	5,0	5,3	10	35	20	✓	21,95 €

*Depending on availability - Dimensions in mm

Our other products



DOG111

Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



PRF4590_E

Bracket for aluminium profile, PRF4590



RPCtc

Swivel castor with central hole, Steel - Polyamide



RPPM

RPP type belt per metre, RPP14 Steel cored polyurethane



AT5-16ECO

AT type timing pulley, Economy range - AT5 aluminium



VELM4

Screw-on base for hook-and-loop strip, Polyamide



CPAS-H

Folding bracket, For heavy loads



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



PHT

Pull handle, Up to 250 °C



DER71

Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



SH0

Parallel axis helical gear, Machined plastic (delrin)



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm

Complementary products



PLN

Cylindrical spacer, Thermoplastic



PLS

Cylindrical spacer, Stainless steel 303