


# Cylindrical magnet

## SmCo

## PLM

- **Smooth finish, shielded system**
- Do not press fit directly into an iron support as a magnetic short circuit will reduce the adhesive force
- Suitable for use in spot welding machines.
- Dimension "H" can be reduced with no loss of adhesive force
- Max working temp : +200°C
- **Material, finish**  
Galvanised steel body,  
Magnetic core SmCo

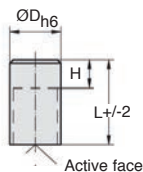

**INCREASED STOCK**

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request



Part number	ØD	L	H	Attraction force (N)	Distance to iron wall/mm	Weight (g)	Stock*	Price each 1 to 5
PLM6-20/SC	6	20	10,0	8	1,5	4,5	✓	6,44 €
PLM8-20/SC	8	20	10,0	22	1,5	8,0	✓	8,11 €
PLM10-20/SC	10	20	8,0	40	2,0	12,0	✓	9,94 €
PLM13-20/SC	13	20	6,0	60	2,5	20,0	-	13,18 €
PLM16-20/SC	16	20	2,0	125	3,0	30,0	-	17,95 €
PLM20-25/SC	20	25	5,0	250	4,0	60,0	-	29,36 €
PLM25-35/SC	25	35	7,0	400	5,0	134,0	-	66,14 €
PLM32-40/SC	32	40	4,5	600	6,0	251,0	-	120,64 €

# Threaded cylindrical magnet

## NdFeB

## PLM

- **Shielded system**
- Suitable for mounting in steel or iron supports
- Can also be used as blind-hole magnets
- Max working temp : +80°C
- **Material, finish**  
Galvanised steel body,  
Magnetic core NdFeB

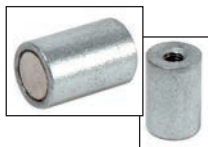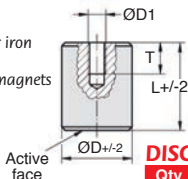

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	ØD	ØD1	L	T	Attraction force (N)	Weight (g)	Stock*	Price each 1 to 5
PLM8-12/N	8	M3	12	5	12	7	✓	7,49 €
PLM10-16/N	10	M4	16	7	24	8	✓	8,59 €
PLM13-18/N	13	M4	18	7	60	18	✓	9,82 €
PLM16-20/N	16	M4	20	7	90	30	✓	10,42 €
PLM20-25/N	20	M5	25	9	135	60	-	18,02 €
PLM25-30/N	25	M6	30	9	190	110	-	38,44 €
PLM35-40/N	35	M8	40	13	300	290	-	66,50 €

 
Dimensions in mm

## Our other products



SUPCC

Self-centering clamping hub steel, With lock nut



P15

Worm and wheel gear reducer, up to 3,75 Nm



SA\_SAKH

Housing for linear bearing, Closed - light load



SH0

Parallel axis helical gear, Steel 20NCD2



T10-BAR

T type tooth bar stock, T10



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



DIL

Lever operated locking bolt, lever clamp



HAR9

Captive C washer, DIN 6371



GLT3-46A

Telescopic drawer with damper.




AXTR

Axle for tensioner pulley, Shaft



RFK28B

 Hypoid gearbox - Stainless steel, up to 3000 Nm



PF45

Worm and wheel gear reducer, up to 40 Nm

## Complementary products



PLM-C

Cylindrical holding magnets, Cylindrical holding magnet



PLM-20SC

Cylindrical magnet, Cylindrical magnet