


Cylindrical holding magnets



PLM AINiCo, calibrated external diameter

- Cylindrical gripping magnet
- Shielded system
- Fixed used a press, shrink fitting or adhesive
- Dimension "H" can be reduced without affecting adhesive force
- Max working temp : 450°C
- **Material, finish**
Galvanised steel body,
Magnetic core AINiCo

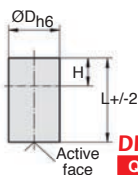

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request


Part number	ØD	L	H	Attraction force (N)	Weight (g)	Stock*	Price each. 1 to 5
PLM6-10/C	6	10	2	1,5	2	✓	5,30 €
PLM8-12/C	8	12	3	3,5	4	✓	5,76 €
PLM10-16/C	10	16	6	7,0	9	✓	6,16 €
PLM13-18/C	13	18	7	10,0	17	-	6,97 €
PLM16-20/C	16	20	5	18,0	29	-	8,84 €
PLM20-25/C	20	25	6	42,0	57	-	11,86 €
PLM25-30/C	25	30	5	96,0	110	-	20,87 €
PLM32-35/C	32	35	3	180,0	200	-	34,90 €
PLM40-45/C	40	45	5	240,0	420	-	78,33 €
PLM50-50/C	50	50	2	420,0	720	-	152,52 €

Flat gripping magnet

PLM

Hard ferrite core

 - Flat magnet without a threaded core
- Shielded system
- These holding magnets can be force fitted or glued into positioning holes
- Max working temp : +200°C
- **Material, finish**
Galvanised steel body,
Hard ferrite magnetic core



DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-15%	-20%	-30%	On request

Part number	ØD	L	Attraction force (N)	Weight (g)	Stock*	Price each. 1 to 5
PLM10-4/P	10 ^{±0,15}	4,5	4	2,0	✓	2,33 €
PLM13-4/P	13 ^{±0,15}	4,5	10	3,0	✓	2,62 €
PLM16-4/P	16 ^{±0,15}	4,5	18	4,5	-	3,10 €
PLM20-6/P	20 ^{±0,15}	6,0	30	10,0	✓	3,76 €
PLM25-7/P	25 ^{±0,15}	7,0	40	19,0	✓	4,12 €
PLM32-7/P	32 ^{±0,20}	7,0	80	30,0	✓	4,46 €
PLM40-8/P	40 ^{±0,20}	8,0	125	55,0	-	6,04 €
PLM50-10/P	50 ^{±0,20}	10,0	220	100,0	-	7,61 €
PLM63-14/P	63 ^{±0,20}	14,0	350	230,0	✓	13,36 €

Dimensions in mm

Our other products



PRF_ROUL

Castor for aluminium profile, No brake



BAC105

Storage bin, 8mm



STU

Stroke rotary bushing, Steel



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50 with counter and handw...



 
TBD

Manual leadscrew table with opposing threads, 20kg



RFVcap

Stainless steel protective cover, Closed protective cover



CFC

Spring loaded position switch, Electric contact



FF40

Offset spur gear reducer, from 59 to 210 Nm



RUR

Wheel, Polyurethane - Aluminium rim (Free



PSEC

Security pull handle, Thermoplastic



PLM-C

Flat gripping magnet, Flat holding magnet



FR

Steel thread inserts, Steel

Complementary products



PLM-20SC

Cylindrical magnet, Cylindrical magnet



PLM-20SC

Threaded cylindrical magnet, With threaded hole