

Cylindrical spacer



PLN

Nylon

- Moulded pillar


- Material:

Nylon

Info.

- As supplied, ends are closed

- Sold by the packet

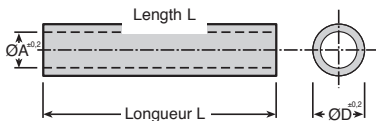

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN3-3/B	3	3,2	3 ±0,15	6	100	✓	7,03 €
PLN3-4/B	3	3,2	4 ±0,15	6	100	✓	7,03 €
PLN3-5/B	3	3,2	5 ±0,15	6	100	✓	7,03 €
PLN3-6/B	3	3,2	6 ±0,15	6	100	✓	7,03 €
PLN3-8/B	3	3,2	8 ±0,15	6	100	✓	7,03 €
PLN3-10/B	3	3,2	10 ±0,15	6	100	✓	7,03 €
PLN3-12/B	3	3,2	12 ±0,20	6	100	✓	8,90 €
PLN3-15/B	3	3,2	15 ±0,20	6	100	✓	8,90 €
PLN3-20/B	3	3,2	20 ±0,20	6	100	-	8,90 €
PLN3-25/B	3	3,2	25 ±0,25	6	100	-	11,17 €
PLN3-30/B	3	3,2	30 ±0,25	6	100	-	11,17 €

*Depending on availability - Dimensions in mm


DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN4-2/B	4	4,2	2 ^{+0,15}	8	100	✓	8,02 €
PLN4-3/B	4	4,2	3 ^{+0,15}	8	100	✓	8,02 €
PLN4-4/B	4	4,2	4 ^{+0,15}	8	100	✓	8,02 €
PLN4-5/B	4	4,2	5 ^{+0,15}	8	100	✓	8,02 €
PLN4-6/B	4	4,2	6 ^{+0,15}	8	100	✓	8,02 €
PLN4-8/B	4	4,2	8 ^{+0,15}	8	100	✓	8,02 €
PLN4-10/B	4	4,2	10 ^{+0,15}	8	100	✓	8,02 €
PLN4-12/B	4	4,2	12 ^{+0,20}	8	100	-	9,30 €
PLN4-15/B	4	4,2	15 ^{+0,20}	8	100	✓	9,30 €
PLN4-18/B	4	4,2	18 ^{+0,20}	8	100	-	9,30 €
PLN4-25/B	4	4,2	25 ^{+0,25}	8	100	-	12,01 €
PLN4-30/B	4	4,2	30 ^{+0,25}	8	100	✓	12,01 €
PLN5-2/B	5	5,2	2 ^{+0,15}	10	100	✓	8,90 €
PLN5-3/B	5	5,2	3 ^{+0,15}	10	100	-	8,90 €
PLN5-4/B	5	5,2	4 ^{+0,15}	10	100	-	8,90 €
PLN5-5/B	5	5,2	5 ^{+0,15}	10	100	-	8,90 €
PLN5-6/B	5	5,2	6 ^{+0,15}	10	100	-	8,90 €
PLN5-8/B	5	5,2	8 ^{+0,15}	10	100	-	8,90 €
PLN5-10/B	5	5,2	10 ^{+0,15}	10	100	-	8,90 €
PLN5-12/B	5	5,2	12 ^{+0,20}	10	100	-	11,19 €
PLN5-15/B	5	5,2	15 ^{+0,20}	10	100	-	11,19 €
PLN5-18/B	5	5,2	18 ^{+0,20}	10	100	-	11,19 €
PLN5-20/B	5	5,2	20 ^{+0,20}	10	100	-	11,19 €
PLN5-25/B	5	5,2	25 ^{+0,25}	10	100	-	14,20 €
PLN5-30/B	5	5,2	30 ^{+0,25}	10	100	-	14,20 €
PLN6-2/B	6	6,2	2 ^{+0,15}	10	100	✓	8,90 €
PLN6-3/B	6	6,2	3 ^{+0,15}	10	100	-	8,90 €
PLN6-4/B	6	6,2	4 ^{+0,15}	10	100	-	8,90 €
PLN6-5/B	6	6,2	5 ^{+0,15}	10	100	✓	8,90 €
PLN6-6/B	6	6,2	6 ^{+0,15}	10	100	✓	8,90 €
PLN6-8/B	6	6,2	8 ^{+0,15}	10	100	✓	8,90 €
PLN6-10/B	6	6,2	10 ^{+0,15}	10	100	✓	8,90 €
PLN6-12/B	6	6,2	12 ^{+0,20}	10	100	✓	11,19 €
PLN6-15/B	6	6,2	15 ^{+0,20}	10	100	✓	11,19 €
PLN6-18/B	6	6,2	18 ^{+0,20}	10	100	✓	11,19 €
PLN6-20/B	6	6,2	20 ^{+0,20}	10	100	✓	11,19 €
PLN6-25/B	6	6,2	25 ^{+0,25}	10	100	-	14,20 €
PLN6-30/B	6	6,2	30 ^{+0,25}	10	100	✓	14,20 €

*Depending on availability - Dimensions in mm

 Our other products



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



CFF

Female rod ends DIN ISO12240-4, Steel / bronze



SSB

Stainless steel bevel gear, 1:1



PDD

Actuating plunger, Non-rotating detector shaft




RPCpl

Swivel castor with plate, Steel - Polyamide



BPFss

Pressed stainless steel flange bearing, Stainless steel

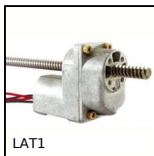

LAT1

1A motorised linear actuator, 1 ampere



WBGV

Lifting ring, Threaded



WW16

Drylin® W slide, slide assembly



BH02

Single housed bearing assembly, Bearing secured with circlips



GDR880

Straight track for slat top chain, Ranges 880 and 881

Complementary products



PLB

Cylindrical spacer, Brass



PLS

Cylindrical spacer, Stainless steel 303