

Cylindrical spacer



PLN

Nylon

- Moulded pillar


- Material:

Nylon

Info.

- As supplied, ends are closed

- Sold by the packet

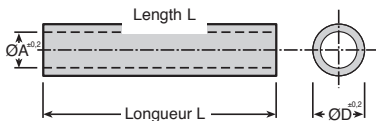

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix -20%	-30%	On request	

Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN3-3/B	3	3,2	3 ±0,15	6	100	✓	7,03 €
PLN3-4/B	3	3,2	4 ±0,15	6	100	✓	7,03 €
PLN3-5/B	3	3,2	5 ±0,15	6	100	✓	7,03 €
PLN3-6/B	3	3,2	6 ±0,15	6	100	✓	7,03 €
PLN3-8/B	3	3,2	8 ±0,15	6	100	✓	7,03 €
PLN3-10/B	3	3,2	10 ±0,15	6	100	✓	7,03 €
PLN3-12/B	3	3,2	12 ±0,20	6	100	✓	8,90 €
PLN3-15/B	3	3,2	15 ±0,20	6	100	✓	8,90 €
PLN3-20/B	3	3,2	20 ±0,20	6	100	-	8,90 €
PLN3-25/B	3	3,2	25 ±0,25	6	100	-	11,17 €
PLN3-30/B	3	3,2	30 ±0,25	6	100	-	11,17 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request


Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN4-2/B	4	4,2	2 ^{+0,15}	8	100	✓	8,02 €
PLN4-3/B	4	4,2	3 ^{+0,15}	8	100	✓	8,02 €
PLN4-4/B	4	4,2	4 ^{+0,15}	8	100	✓	8,02 €
PLN4-5/B	4	4,2	5 ^{+0,15}	8	100	✓	8,02 €
PLN4-6/B	4	4,2	6 ^{+0,15}	8	100	✓	8,02 €
PLN4-8/B	4	4,2	8 ^{+0,15}	8	100	✓	8,02 €
PLN4-10/B	4	4,2	10 ^{+0,15}	8	100	✓	8,02 €
PLN4-12/B	4	4,2	12 ^{+0,20}	8	100	-	9,30 €
PLN4-15/B	4	4,2	15 ^{+0,20}	8	100	✓	9,30 €
PLN4-18/B	4	4,2	18 ^{+0,20}	8	100	-	9,30 €
PLN4-25/B	4	4,2	25 ^{+0,25}	8	100	-	12,01 €
PLN4-30/B	4	4,2	30 ^{+0,25}	8	100	✓	12,01 €
PLN5-2/B	5	5,2	2 ^{+0,15}	10	100	✓	8,90 €
PLN5-3/B	5	5,2	3 ^{+0,15}	10	100	-	8,90 €
PLN5-4/B	5	5,2	4 ^{+0,15}	10	100	-	8,90 €
PLN5-5/B	5	5,2	5 ^{+0,15}	10	100	-	8,90 €
PLN5-6/B	5	5,2	6 ^{+0,15}	10	100	-	8,90 €
PLN5-8/B	5	5,2	8 ^{+0,15}	10	100	-	8,90 €
PLN5-10/B	5	5,2	10 ^{+0,15}	10	100	-	8,90 €
PLN5-12/B	5	5,2	12 ^{+0,20}	10	100	-	11,19 €
PLN5-15/B	5	5,2	15 ^{+0,20}	10	100	-	11,19 €
PLN5-18/B	5	5,2	18 ^{+0,20}	10	100	-	11,19 €
PLN5-20/B	5	5,2	20 ^{+0,20}	10	100	-	11,19 €
PLN5-25/B	5	5,2	25 ^{+0,25}	10	100	-	14,20 €
PLN5-30/B	5	5,2	30 ^{+0,25}	10	100	-	14,20 €
PLN6-2/B	6	6,2	2 ^{+0,15}	10	100	✓	8,90 €
PLN6-3/B	6	6,2	3 ^{+0,15}	10	100	-	8,90 €
PLN6-4/B	6	6,2	4 ^{+0,15}	10	100	-	8,90 €
PLN6-5/B	6	6,2	5 ^{+0,15}	10	100	✓	8,90 €
PLN6-6/B	6	6,2	6 ^{+0,15}	10	100	✓	8,90 €
PLN6-8/B	6	6,2	8 ^{+0,15}	10	100	✓	8,90 €
PLN6-10/B	6	6,2	10 ^{+0,15}	10	100	✓	8,90 €
PLN6-12/B	6	6,2	12 ^{+0,20}	10	100	✓	11,19 €
PLN6-15/B	6	6,2	15 ^{+0,20}	10	100	✓	11,19 €
PLN6-18/B	6	6,2	18 ^{+0,20}	10	100	✓	11,19 €
PLN6-20/B	6	6,2	20 ^{+0,20}	10	100	✓	11,19 €
PLN6-25/B	6	6,2	25 ^{+0,25}	10	100	-	14,20 €
PLN6-30/B	6	6,2	30 ^{+0,25}	10	100	✓	14,20 €

*Depending on availability - Dimensions in mm

Our other products



 NCT
Square tube connector, Fixed angle



RPP14
RPP heavy duty timing belt, RPP14



CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



CDC
Conical compression spring, Conical



BABPass
Hardened stainless steel ball pin with ring, With grip ring



PAT123
Pressed stainless steel articulating foot Ø123, Ø 123



SSHBRA
Stainless steel bevel gear, 1,5:1 2:1 3:1




LVT
Miniature motorised actuator 2A, 2 amperes



BIM
Indexing plunger mini, miniature



 PM2
Worm and wheel set, Hardened steel



PF40NM
Worm and wheel gear reducer, up to 18 Nm



RPP
Connecting plate for RPP type timing belts, RRP5

Complementary products



PLB
Cylindrical spacer, Brass



PLS
Cylindrical spacer, Stainless steel 303