

Cylindrical spacer




PLN

Thermoplastic

- Moulded pillar
- Material:
natural polypropylene
- Max temp. 70°C

Info.

- As supplied, ends are closed
- Sold by the packet

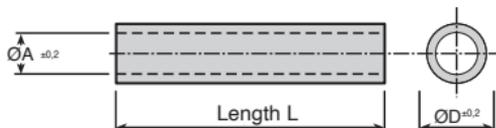

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN3-3/B	3	3,2	3 ±0,15	6	100	✓	8,23 €
PLN3-4/B	3	3,2	4 ±0,15	6	100	✓	8,23 €
PLN3-5/B	3	3,2	5 ±0,15	6	100	✓	8,23 €
PLN3-6/B	3	3,2	6 ±0,15	6	100	✓	8,23 €
PLN3-8/B	3	3,2	8 ±0,15	6	100	✓	8,23 €
PLN3-10/B	3	3,2	10 ±0,15	6	100	✓	8,23 €
PLN3-12/B	3	3,2	12 ±0,20	6	100	✓	10,40 €
PLN3-15/B	3	3,2	15 ±0,20	6	100	✓	10,40 €
PLN3-20/B	3	3,2	20 ±0,20	6	100	-	10,40 €
PLN3-25/B	3	3,2	25 ±0,25	6	100	-	13,06 €
PLN3-30/B	3	3,2	30 ±0,25	6	100	-	13,06 €

*Depending on availability - Dimensions in mm

DISCOUNTS

N° packets	1+	5+	20+	100+
Discount	Prix	-20%	-30%	On request

Part number	Nominal ØA	ØA	L	ØD	Qty. per packet	Stock*	Price per packet
PLN4-2/B	4	4,2	2 ^{+0,15}	8	100	✓	9,38 €
PLN4-3/B	4	4,2	3 ^{+0,15}	8	100	✓	9,38 €
PLN4-4/B	4	4,2	4 ^{+0,15}	8	100	✓	9,38 €
PLN4-5/B	4	4,2	5 ^{+0,15}	8	100	✓	9,38 €
PLN4-6/B	4	4,2	6 ^{+0,15}	8	100	✓	9,38 €
PLN4-8/B	4	4,2	8 ^{+0,15}	8	100	✓	9,38 €
PLN4-10/B	4	4,2	10 ^{+0,15}	8	100	✓	9,38 €
PLN4-12/B	4	4,2	12 ^{+0,20}	8	100	-	10,87 €
PLN4-15/B	4	4,2	15 ^{+0,20}	8	100	✓	10,87 €
PLN4-18/B	4	4,2	18 ^{+0,20}	8	100	-	10,87 €
PLN4-25/B	4	4,2	25 ^{+0,25}	8	100	-	14,05 €
PLN4-30/B	4	4,2	30 ^{+0,25}	8	100	✓	14,05 €
PLN5-2/B	5	5,2	2 ^{+0,15}	10	100	-	10,40 €
PLN5-3/B	5	5,2	3 ^{+0,15}	10	100	-	10,40 €
PLN5-4/B	5	5,2	4 ^{+0,15}	10	100	-	10,40 €
PLN5-5/B	5	5,2	5 ^{+0,15}	10	100	-	10,40 €
PLN5-6/B	5	5,2	6 ^{+0,15}	10	100	-	10,40 €
PLN5-8/B	5	5,2	8 ^{+0,15}	10	100	-	10,40 €
PLN5-10/B	5	5,2	10 ^{+0,15}	10	100	-	10,40 €
PLN5-12/B	5	5,2	12 ^{+0,20}	10	100	-	13,08 €
PLN5-15/B	5	5,2	15 ^{+0,20}	10	100	✓	13,08 €
PLN5-18/B	5	5,2	18 ^{+0,20}	10	100	-	13,08 €
PLN5-20/B	5	5,2	20 ^{+0,20}	10	100	-	13,08 €
PLN5-25/B	5	5,2	25 ^{+0,25}	10	100	-	16,61 €
PLN5-30/B	5	5,2	30 ^{+0,25}	10	100	-	16,61 €
PLN6-2/B	6	6,2	2 ^{+0,15}	10	100	✓	10,40 €
PLN6-3/B	6	6,2	3 ^{+0,15}	10	100	-	10,40 €
PLN6-4/B	6	6,2	4 ^{+0,15}	10	100	✓	10,40 €
PLN6-5/B	6	6,2	5 ^{+0,15}	10	100	✓	10,40 €
PLN6-6/B	6	6,2	6 ^{+0,15}	10	100	✓	10,40 €
PLN6-8/B	6	6,2	8 ^{+0,15}	10	100	✓	10,40 €
PLN6-10/B	6	6,2	10 ^{+0,15}	10	100	✓	10,40 €
PLN6-12/B	6	6,2	12 ^{+0,20}	10	100	✓	13,08 €
PLN6-15/B	6	6,2	15 ^{+0,20}	10	100	✓	13,08 €
PLN6-18/B	6	6,2	18 ^{+0,20}	10	100	-	13,08 €
PLN6-20/B	6	6,2	20 ^{+0,20}	10	100	✓	13,08 €
PLN6-25/B	6	6,2	25 ^{+0,25}	10	100	-	16,61 €
PLN6-30/B	6	6,2	30 ^{+0,25}	10	100	✓	16,61 €

*Depending on availability - Dimensions in mm

Cylindrical spacer



PLB

Brass

- Machined pillar

- Material:


Brass

Option

- Alternative lengths are available

Info.

- Sold by the packet

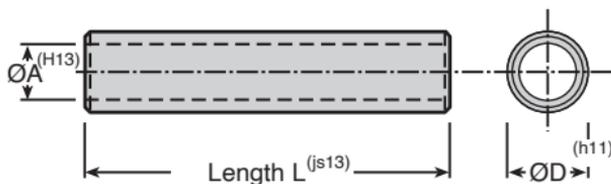

DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB2-1/B	2,0	2,2	4	1	20	✓	2,80 €
PLB2-2/B	2,0	2,2	4	2	20	✓	2,93 €
PLB2-3/B	2,0	2,2	4	3	20	-	3,09 €
PLB2-4/B	2,0	2,2	4	4	20	✓	3,29 €
PLB2-5/B	2,0	2,2	4	5	20	✓	3,39 €
PLB2-8/B	2,0	2,2	4	8	20	✓	3,66 €
PLB2-10/B	2,0	2,2	4	10	20	-	4,02 €
PLB2-12/B	2,0	2,2	4	12	20	-	4,19 €
PLB2.5-1/B	2,5	2,5	5	1	20	-	3,83 €
PLB2.5-2/B	2,5	2,5	5	2	20	-	3,09 €
PLB2.5-3/B	2,5	2,5	5	3	20	-	3,29 €
PLB2.5-4/B	2,5	2,5	5	4	20	✓	3,46 €
PLB2.5-5/B	2,5	2,5	5	5	20	✓	3,66 €
PLB2.5-8/B	2,5	2,5	5	8	20	-	4,19 €
PLB2.5-10/B	2,5	2,5	5	10	20	-	4,52 €
PLB2.5-12/B	2,5	2,5	5	12	20	-	4,92 €
PLB2.5-20/B	2,5	2,5	5	20	20	✓	7,62 €

*Depending on availability - Dimensions in mm

DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLB3-2/B	3,0	3,2	6	2	20	✓	2,80 €
PLB3-3/B	3,0	3,2	6	3	20	✓	3,09 €
PLB3-4/B	3,0	3,2	6	4	20	✓	3,29 €
PLB3-5/B	3,0	3,2	6	5	20	✓	3,46 €
PLB3-8/B	3,0	3,2	6	8	20	✓	4,19 €
PLB3-10/B	3,0	3,2	6	10	20	✓	4,74 €
PLB3-12/B	3,0	3,2	6	12	20	✓	5,27 €
PLB3-15/B	3,0	3,2	6	15	20	✓	6,02 €
PLB3-20/B	3,0	3,2	6	20	20	✓	7,51 €
PLB3-25/B	3,0	3,2	6	25	20	-	9,99 €
PLB3-30/B	3,0	3,2	6	30	20	-	12,03 €
PLB4-2/B	4,0	4,3	8	2	20	✓	3,11 €
PLB4-3/B	4,0	4,3	8	3	20	✓	3,46 €
PLB4-4/B	4,0	4,3	8	4	20	✓	3,83 €
PLB4-5/B	4,0	4,3	8	5	20	✓	4,04 €
PLB4-8/B	4,0	4,3	8	8	20	✓	5,29 €
PLB4-10/B	4,0	4,3	8	10	20	✓	6,20 €
PLB4-12/B	4,0	4,3	8	12	20	✓	7,29 €
PLB4-15/B	4,0	4,3	8	15	20	✓	8,38 €
PLB4-18/B	4,0	4,3	8	18	20	-	9,46 €
PLB4-20/B	4,0	4,3	8	20	20	✓	10,55 €
PLB4-25/B	4,0	4,3	8	25	20	-	14,00 €
PLB4-30/B	4,0	4,3	8	30	20	✓	16,47 €
PLB5-2/B	5,0	5,3	10	2	20	-	4,21 €
PLB5-3/B	5,0	5,3	10	3	20	✓	4,75 €
PLB5-4/B	5,0	5,3	10	4	20	✓	5,29 €
PLB5-5/B	5,0	5,3	10	5	20	✓	5,82 €
PLB5-8/B	5,0	5,3	10	8	20	✓	8,95 €
PLB5-10/B	5,0	5,3	10	10	20	✓	10,17 €
PLB5-12/B	5,0	5,3	10	12	20	✓	10,93 €
PLB5-15/B	5,0	5,3	10	15	20	✓	12,91 €
PLB5-20/B	5,0	5,3	10	20	20	✓	16,47 €
PLB5-25/B	5,0	5,3	10	25	20	✓	20,16 €
PLB5-30/B	5,0	5,3	10	30	20	✓	24,69 €
PLB5-35/B	5,0	5,3	10	35	20	✓	29,14 €

*Depending on availability - Dimensions in mm


- Machined pillar, female/female

- Material:

Stainless steel 303

Info.

- Sold by the packet

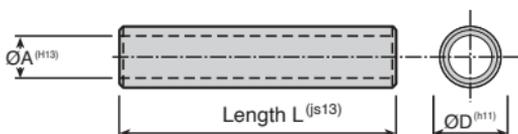

DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal		ØA	ØD	L	Qty. per packet	Stock*	Price per packet
	ØA	ØA						
PLS3-5/B	3	3,2	6	5	20	✓	28,59 €	
PLS3-6/B	3	3,2	6	6	20	✓	30,13 €	
PLS3-8/B	3	3,2	6	8	20	✓	31,36 €	
PLS3-10/B	3	3,2	6	10	20	✓	33,53 €	
PLS3-12/B	3	3,2	6	12	20	✓	34,33 €	
PLS3-18/B	3	3,2	6	18	20	-	38,13 €	
PLS3-25/B	3	3,2	6	25	20	-	42,71 €	
PLS4-5/B	4	4,3	8	5	20	✓	31,35 €	
PLS4-6/B	4	4,3	8	6	20	✓	33,14 €	
PLS4-8/B	4	4,3	8	8	20	✓	34,55 €	
PLS4-10/B	4	4,3	8	10	20	✓	36,87 €	
PLS4-12/B	4	4,3	8	12	20	-	37,76 €	
PLS4-15/B	4	4,3	8	15	20	✓	40,01 €	
PLS4-20/B	4	4,3	8	20	20	-	42,89 €	
PLS4-25/B	4	4,3	8	25	20	✓	46,92 €	
PLS4-30/B	4	4,3	8	30	20	✓	50,28 €	

*Depending on availability - Dimensions in mm