


# Cylindrical spacer



## PLS

## Stainless steel 303

- Machined pillar, female/female
- Material:  
Stainless steel 303
- Sold by the packet

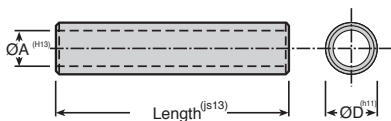

### DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal ØA	ØA	ØD	L	Qty. per packet	Stock*	Price per packet
PLS3-5/B	3	3,2	6	5	20	✓	26,45 €
PLS3-6/B	3	3,2	6	6	20	✓	27,88 €
PLS3-8/B	3	3,2	6	8	20	✓	28,94 €
PLS3-10/B	3	3,2	6	10	20	✓	30,88 €
PLS3-12/B	3	3,2	6	12	20	✓	31,58 €
PLS3-18/B	3	3,2	6	18	20	-	34,97 €
PLS3-25/B	3	3,2	6	25	20	-	39,03 €
PLS4-5/B	4	4,3	8	5	20	✓	28,94 €
PLS4-6/B	4	4,3	8	6	20	✓	30,52 €
PLS4-8/B	4	4,3	8	8	20	✓	31,77 €
PLS4-10/B	4	4,3	8	10	20	✓	33,84 €
PLS4-12/B	4	4,3	8	12	20	✓	34,63 €
PLS4-15/B	4	4,3	8	15	20	-	36,61 €
PLS4-20/B	4	4,3	8	20	20	-	39,18 €
PLS4-25/B	4	4,3	8	25	20	✓	42,77 €
PLS4-30/B	4	4,3	8	30	20	✓	45,75 €

\*Depending on availability - Dimensions in mm

## Our other products



LVT  
Miniature motorised  
actuator 1A, 1 ampere



UCF\_SS  
Stainless steel flanged  
bearing, Stainless  
steel



PGT  
Sliding profile, Sliding  
panel support



CFF  
Female rod ends DIN  
ISO12240-4, Steel /  
bronze




G-ECO  
Eco range Spur gear,  
Steel C45




AZY  
Cylindrical elastomount,  
Steel



PGMT  
Pull handle, Steel

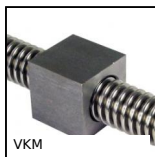

VKM  
Square steel nut,  
Steel - 1 thread

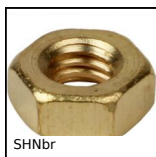


SHNbr  
Hexagonal nut  
DIN934, Brass



CHT  
Asynchronous AC  
Motor, 0.18 to 0.55kW



PCLA\_T  
Technopolymer  
clamping lever - male,  
Plastic

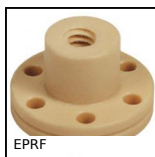

EPRF  
High helix leadscrew,  
Flanged nut - up to  
40mm per rotation

## Complementary products



PLN  
Cylindrical spacer,  
Thermoplastic



PLB  
Cylindrical spacer,  
Brass