


Cylindrical spacer



PLS

Stainless steel 303

- Machined pillar, female/female
- Material:
Stainless steel 303
- Sold by the packet

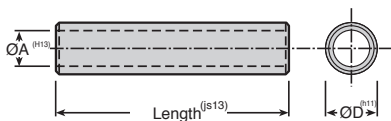

DISCOUNTS

No pack	1+	5+	20+	100+
Disc	List	-20%	-30%	On request

Part number	Nominal		ØA	ØD	L	Qty. per packet	Stock*	Price per packet
	ØA	ØA						
PLS3-5/B	3	3,2	6	5	20	✓	26,45 €	
PLS3-6/B	3	3,2	6	6	20	✓	27,88 €	
PLS3-8/B	3	3,2	6	8	20	✓	28,94 €	
PLS3-10/B	3	3,2	6	10	20	✓	30,88 €	
PLS3-12/B	3	3,2	6	12	20	✓	31,58 €	
PLS3-18/B	3	3,2	6	18	20	-	34,97 €	
PLS3-25/B	3	3,2	6	25	20	-	39,03 €	
PLS4-5/B	4	4,3	8	5	20	✓	28,94 €	
PLS4-6/B	4	4,3	8	6	20	✓	30,52 €	
PLS4-8/B	4	4,3	8	8	20	✓	31,77 €	
PLS4-10/B	4	4,3	8	10	20	✓	33,84 €	
PLS4-12/B	4	4,3	8	12	20	-	34,63 €	
PLS4-15/B	4	4,3	8	15	20	✓	36,61 €	
PLS4-20/B	4	4,3	8	20	20	-	39,18 €	
PLS4-25/B	4	4,3	8	25	20	✓	42,77 €	
PLS4-30/B	4	4,3	8	30	20	✓	45,75 €	

*Depending on availability - Dimensions in mm

Our other products



AT10courroie

AT type timing belt,
AT10 Steel cored
polyurethane



AXTR

Axle for tensioner
pulley, Shaft



F7-SN

Multifunction display,
Articulated support



SVT_CH

Screwjack - pivot
mounting, Pivoting
bracket



NT12

Spur gear coaxial
gearbox, from 32 to
85 Nm - Inline



HTD8M_50

HTD Heavy duty
timing pulley, HTD8
Steel



DB

Steel bevel gear, 2:1



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for clevis



CLASS

Stainless steel
indexing handle -
female, Stainless steel



PCS62SS

Chain sprocket -
Stainless steel,
15.875mm (DIN)



WJUM20

Drylin® W bearing
block, Slide



BLHB20

Right angled gearbox,
bored shafts, up to
1.77 Nm

Complementary products



PLN

Cylindrical spacer,
Thermoplastic



PLB

Cylindrical spacer,
Brass