



Wheel in bronze or **machined** plastic **Module 3.0**

Info.

- Pitch **9.425mm**
- To order, add the number of starts on the worm to the wheel's part number.
E.g: worm **W3-1**, wheel **M3-20/1**
- The use of a delrin worm with a delrin wheel is only recommended for occasional use. The use of a delrin worm with a steel wheel is preferred.

Torque and power indication
for 50 teeth at 1000 rpm (input)

WHEEL material	Bronze Nm (kW)	Delrin Nm (kW)
Steel	139 (0.291)	69 (0.145)
Hardened steel	200 (0.422)	-
Delrin	-	27 (0.058)

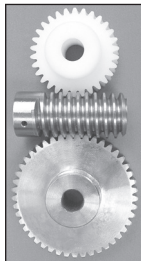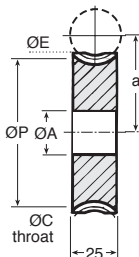

DISCOUNT Bronze

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

DISCOUNT Delrin

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number		Z	Centres					Price each 1 to 5	
Bronze	Plastic	Teeth	ØP	a	ØC	ØE	ØA	Bronze	Plastic
PM3-15	ZPM3-15	15	45	40,00	51	54	25	94,01 €	67,61 €
PM3-20	ZPM3-20	20	60	47,50	66	69	25	118,83 €	85,49 €
PM3-25	ZPM3-25	25	75	55,00	81	84	25	143,08 €	102,91 €
PM3-30	ZPM3-30	30	90	62,50	96	99	25	206,12 €	148,33 €
PM3-40	ZPM3-40	40	120	77,50	126	129	25	529,14 €	192,74 €
PM3-50	ZPM3-50	50	150	92,50	156	159	25	On request 342,19 €	
PM3-55	ZPM3-55	55	165	100,00	171	174	25	On request 397,61 €	

Wheels available up to this size

PM3-285	ZPM3-285	285	Dimensions: contact us				On request	On request
---------	----------	-----	------------------------	--	--	--	------------	------------

Dimensions in mm

Worm and wheel set



Module 3.0 Worm in steel or machined plastic




- Pitch 9.425mm
- Machined parts
- Pressure angle 20°
- Right handed lead angle
- Materials:
Worm: Steel 20NCD2 or Delrin plastic
Wheel: bronze CuAl10NiFe4 or Delrin plastic
- Delrin: Working temp. -50°C to +80°C




Options


- Left handed lead angle
- Wheel can have from 15 to 285 teeth

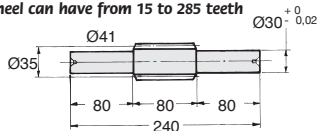

Steel worm with shaft (SW)

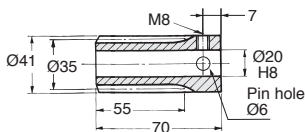

Steel (W) or plastic (ZW) worm with bore

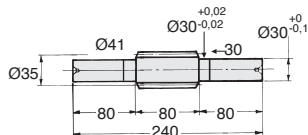

Plastic worm with shaft (ZSW)

DISCOUNT Steel

Qty	1+	6+	20+	50+
Disc.	List -12%	-25%	On request	

DISCOUNT Delrin

Qty	1+	6+	30+
Disc.	List -22%	On request	

Part number		No. of starts	Lead angle	Price each 1 to 5	
Worm with bore	Worm with shaft			Worm with bore	Worm with shaft
Non hardened steel					
W3-1	SW3-1	1	4°54'	135,87 €	194,42 €
W3-2	SW3-2	2	9°44'	140,36 €	206,38 €
W3-3	SW3-3	3	14°25'	144,53 €	215,03 €
W3-4	SW3-4	4	18°55'	150,23 €	223,53 €
Hardened steel					
WH3-1	SWH3-1	1	4°54'	174,40 €	266,15 €
WH3-2	SWH3-2	2	9°44'	179,03 €	258,67 €
WH3-3	SWH3-3	3	14°25'	188,04 €	262,86 €
WH3-4	SWH3-4	4	18°55'	195,56 €	275,97 €
Delrin					
ZW3-1	ZSW3-1	1	4°54'	107,62 €	149,58 €
ZW3-2	ZSW3-2	2	9°44'	110,75 €	155,13 €
ZW3-3	ZSW3-3	3	14°25'	113,79 €	161,43 €
ZW3-4	ZSW3-4	4	18°55'	117,87 €	167,58 €

Dimensions in mm

Our other products



AHEX

Hexagonal shaft,
Hexagonal shaft



PRF_BASE

Base plate for
aluminium profile,
Base plate



SEH

Horizontal stirrup
toggle clamp,
Horizontal stirrup
clamp - steel



PRF_FIX_STD

Fastener for
aluminium profile,
Standard fastener



SRP

Slotted spring pin
ISO8752, Split ISO
8752



PSG25S

Spur gear - precision
range, Stainless steel
303



SBS_L

Chain link, Stainless
steel




PR40

Articulated foot Ø40,
Ø 40



PPS

 Lifting ring, Universal
threaded




JFM

Flanged polymer
bush, Universal
polymer



PW_PWG2

 Worm - precision
range, Steel



PM4

Worm and wheel set,
Machined plastic
(delrin)

Complementary products



PM3

Worm and wheel set,
Non hardened steel



PM3

Worm and wheel set,
Hardened steel