

# Solid foot mount for heavy loads

## PML


## Max load 90,000 N

- Levelling foot mount for very heavy loads
- Solid foot
- Hollow stem
- Fine thread pitch gives accurate levelling
- Oscillation  $\pm 2^\circ$
- Materials:
  - Base: steel with yellow coated finish
  - Stem: Chromed steel




### Applications

- Machine tools, assembly machines, automated lines

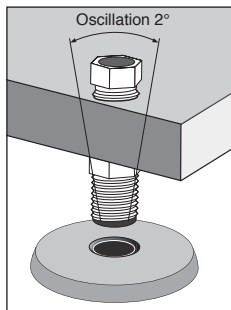

Typical application

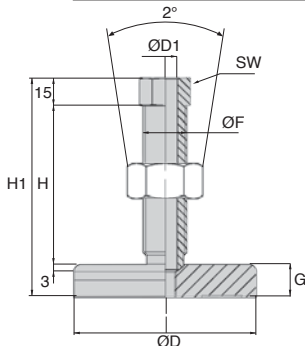

### DISCOUNTS

Qty	1+	6+	10+	15+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	SW	ØF	G	H	H1	Static load (N)	Price each 1 to 5
PML100-24C-87	100	13	24	M24x2	18	87	120	60000	24,79 €
PML100-24C-141	100	13	24	M24x2	18	141	174	60000	27,38 €
PML120-35C-100	120	22	41	M35x2	25	100	140	90000	68,74 €
PML120-35C-177	120	22	41	M35x2	25	177	217	90000	72,46 €
PML120-36C-100	120	22	41	M36x2	25	100	140	90000	68,74 €
PML150-35C-100	150	22	41	M35x2	25	100	140	90000	76,37 €
PML150-35C-177	150	22	41	M35x2	25	177	217	90000	80,60 €
PML150-36C-100	150	22	41	M36x2	25	100	140	90000	76,37 €

Dimensions in mm

## Our other products



SCE

U-shaped cable clamp, Steel



GE\_ET\_2RS

Spherical bushing, Hard chromium / Teflon contact with seals



ACLDBB

Closing mechanism for aluminium profile, Dual ball catch



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt



GG1

Ground spur gear, Heat treated steel



SBF

Sealed flange bearing unit for Food Industry, cover



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



NRR

Adjustable support clamp, Adjustable support clamp



HTD14M\_85

HTD Heavy duty timing pulley, HTD14 Cast



BEAS

Star shaped anti-static handle, Star, anti-static



H0

Crossed helical gear, crossed axis at 90°, Steel 20NCD2



MSP3815

Masterplate® glueable insert, rectangular, rectangular with threaded...

Complementary products