

Multi-sector enclosure/door handle

PO

Back to back mounting

- Ideal for back mounting, i.e. a PO handle used on one side with a PO-M handle on the other (see typical application)

- Colour: matt black

- Materials:

Handle: Fibreglass reinforced Technopolymer

Insert: Brass (PO-M version)

- PO version has a smooth bored hole for socket head screw

- PO-M has a blind threaded insert



PO version



PO-M version



Black



Red: safety

Add: /R
to end of part N°



Orange:

furniture, kitchens

Add: /O
to end of part N°




Grey: food industry

Add: /G
to end of part N°




White: medical



Add: /W
to end of part N°

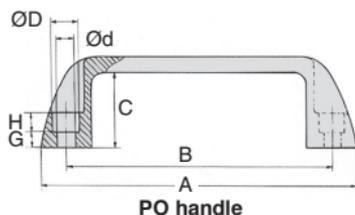

PO handle

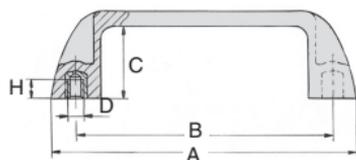

PO-M handle

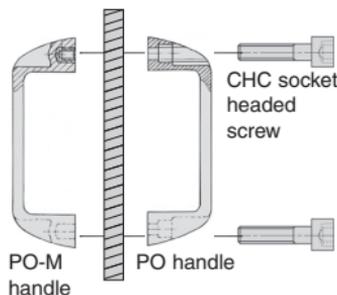 

Back to back mounting

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	B	A	E	F	C	G	H	ØD	Ød	Stock*	Price each 1 to 5
With smooth hole											
PO93-6	93,5	112	21	36	30	6	7	10,5	6,5	✓	3,69 €
PO117-6	117	139	26	41	34	6	9	10,5	6,5	✓	4,01 €
PO117-8	117	139	26	41	34	6	9	13,0	8,5	✓	4,01 €
PO132-6	132	156	27	45	37	9	7	10,5	6,5	✓	5,47 €
PO132-8	132	156	27	45	37	7	9	13,0	8,5	✓	8,02 €
PO179-8	179	204	28	50	42	8	9	13,0	8,5	✓	8,02 €
With threaded hole											
PO93-M5	93,5	112	21	36	30	-	9	M5	-		5,35 €
PO93-M6	93,5	112	21	36	30	-	9	M6	-	✓	5,63 €
PO117-M6	117	139	26	41	34	-	9	M6	-	✓	5,93 €
PO117-M8	117	139	26	41	34	-	9	M8	-	✓	5,93 €
PO132-M6	132	156	27	45	37	-	9	M6	-	✓	6,61 €
PO132-M8	132	156	27	45	37	-	9	M8	-	✓	6,61 €
PO179-M8	179	204	28	50	42	-	9	M8	-	✓	9,57 €

*Depending on availability - Dimensions in mm

Our other products



RTL450

Self-centering locking assembly, High torque



DOMI50

Connecting kits, XY linking kit



DIA

Ring operated locking bolt, with ring



CHC

Socket headed screw, Steel class 12.19



HTD8M_20

HTD Heavy duty timing pulley, HTD8 Steel



SC2

2 part rigid shaft clamp, Clamping jaw



PTCR

Adjustable furniture foot, square tube



TBD

Manual leadscrew table with opposing threads, 20kg



SBF

Sealed flange bearing unit for Food Industry, cover



CHM63

Worm and wheel gear reducer, up to 196 Nm



M1


Worm and wheel set, Non hardened steel



PDM_PDV

Detectable plastic palm grip, blue thermoplastic

Complementary products

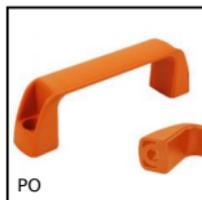

PO

Pull handle - Multi-sector, Smooth hole



CHC

Socket headed screw, Steel class 12.19



PCATherm

Pull handle, Thermoplastic



PSEC

Security pull handle, Thermoplastic