

Multi-sector enclosure/door handle

PO

Back to back mounting

- Ideal for back mounting, i.e. a PO handle used on one side with a PO-M handle on the other (see typical application)

- Colour: matt black

- Materials:

Handle: Fibreglass reinforced Technopolymer

Insert: Brass (PO-M version)

- PO version has a smooth bored hole for socket head screw

- PO-M has a blind threaded insert



PO version



PO-M version



Black



Red: safety

Add: /R
to end of part N°



Orange:

furniture, kitchens

Add: /O
to end of part N°




 


Grey: food industry

Add: /G
to end of part N°



White: medical

Add: /B
to end of part N°

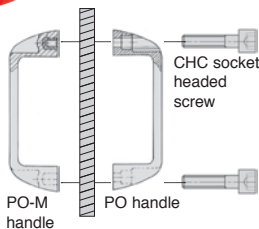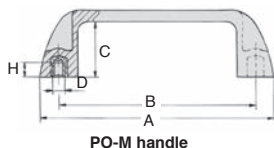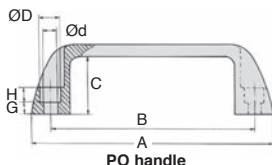

Back to back mounting

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	B	A	E	F	C	G	H	ØD	Ød	Stock*	Price each 1 to 5
With smooth hole											
PO93-6	93,5	112	21	36	30	6	7	10,5	6,5	✓	3,68 €
PO117-6	117	139	26	41	34	6	9	10,5	6,5	✓	4,00 €
PO117-8	117	139	26	41	34	6	9	13,0	8,5	✓	4,00 €
PO132-6	132	156	27	45	37	9	7	10,5	6,5	✓	5,46 €
PO132-8	132	156	27	45	37	7	9	13,0	8,5	✓	8,02 €
PO179-8	179	204	28	50	42	8	9	13,0	8,5	✓	8,02 €
With threaded hole											
PO93-M5	93,5	112	21	36	30	-	9	M5	-		5,35 €
PO93-M6	93,5	112	21	36	30	-	9	M6	-	✓	5,63 €
PO117-M6	117	139	26	41	34	-	9	M6	-	✓	5,92 €
PO117-M8	117	139	26	41	34	-	9	M8	-	✓	5,92 €
PO132-M6	132	156	27	45	37	-	9	M6	-	✓	6,61 €
PO132-M8	132	156	27	45	37	-	9	M8	-	✓	6,61 €
PO179-M8	179	204	28	50	42	-	9	M8	-	✓	9,56 €

*Depending on availability - Dimensions in mm

Our other products



CLSr-CLLr

Swivelling base clevis,
Steel short



CDC

Compression spring,
Conical



CMM

Rod end, Steel /
bronze



G-ECO

Spur gear, Steel C45



RURt

Wheel pivoting with
central hole,
Polyurethane -
Aluminium rim (Free



RFK28B

Hypoid gearbox -
Stainless steel, up to
130 Nm



BOX-TOR-A

Box set of Nitrile O-
rings, 2.90 x 1.78mm
to 28.17 x 3.53



CFF_SS

Rod end, Stainless
steel / bronze -
Economy range



PARF110

Rigid foot, Swivelling
Ø110



IBJ

Ball and socket joint,
Steel



HG6

Spur gear, Steel
20NCD2



DGSA

Rod end, Steel / steel
- Economy range

Complementary products



PO

Housing handle - Multi-
sector, Smooth hole



CHC

Socket headed screw
CHC - DIN 912, Steel
class 12.19