

# Pad eye on square mounting plate **Sta**



## PPCSS

## Stainless steel

- Screwed mounting plate

- Material:

316 stainless steel

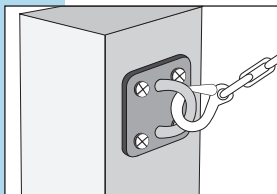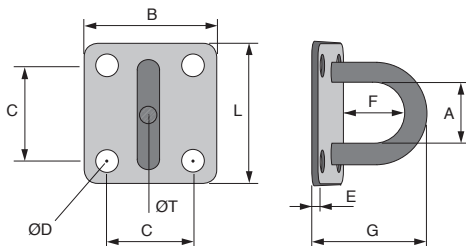

Typical application

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	ØD	C	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPC5-16/SS	5	16	30	35	5	19	2,8	15	23	0,027	-	3,75 €
PPC6-20/SS	6	20	35	40	5,5	24	2,8	17	26	0,040	✓	5,02 €
PPC8-23/SS	8	23	40	50	5,5	29	2,8	21	32	0,068	✓	7,80 €

Dimensions in mm

## Our other products



STC  
Shock Absorber - stop collar, Universal flange



WS20  
Drylin® W rail, Rail



STRIP  
Sealing brush strip, 3m length



PRF\_PF  
Anchoring bracket for aluminium profile, Anchor



PF40  
Worm and wheel gear reducer, up to 18 Nm



CPAS-H  
Folding bracket, For heavy loads



SLH  
Horizontal toggle clamp, Horizontal Lever Clamp - steel



PRES4HR  
Manual workbench press, Force up to 600kg



UTKswcr  
Utilitrak® 3 wheels carriage, Steel roller carriage



BSB  
Ball screw bearing unit, Support

 


ACLRP  
Wheel for aluminium profile, Integrated bearing



BOX-WM  
Box set of washer - DIN125, Box set of steel washers

## Complementary products



CAB  
Stainless steel cable, Stainless steel



MACss  
Stainless steel carabiner, Stainless steel



SCA\_SS  
Stainless steel flat cable clamp, Stainless steel



TAC\_SS  
Stainless steel rigging screw (hook/eye), Stainless steel