

Pad eye on square mounting plate **Sta**



PPCSS

Stainless steel

- Screwed mounting plate

- Material:

316 stainless steel

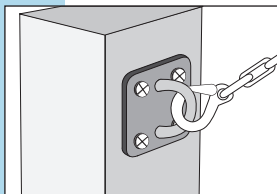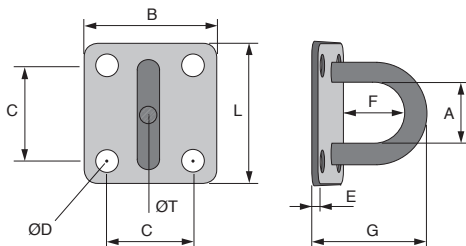

Typical application

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	ØD	C	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPC5-16/SS	5	16	30	35	5	19	2,8	15	23	0,027	-	3,75 €
PPC6-20/SS	6	20	35	40	5,5	24	2,8	17	26	0,040	✓	5,02 €
PPC8-23/SS	8	23	40	50	5,5	29	2,8	21	32	0,068	✓	7,80 €

Dimensions in mm

Our other products



 
CMM

Male rod ends DIN ISO12240-4, Steel / bronze



VDSQ

Sliding lock adjustment system, Sliding lock for square profile



EZYSS

Stainless steel cylindrical stop, stainless steel



SCE

U-shaped cable clamp, Steel



CHALss

Piano hinge, Stainless steel



 
PTMC

Telescopic furniture foot, square plate



VEL

Self-gripping cable strip, electric and pneumatic cables



T0

Torsion spring, Stainless steel




RLX

Free running conveyor roller, PVC



INS100

 Self tapping inserts-coarse thread, Coarse



JFM

 
Flanged polymer bush, Universal



ESCON

Speed controller 5A, 5 A

Complementary products



CAB

Stainless steel cable, Stainless steel



MACss

Stainless steel carabiner, Stainless steel



SCA_SS

Stainless steel flat cable clamp, Stainless steel



TAC_SS

Stainless steel rigging screw (hook/eye), Stainless steel