

# Pad eye on square mounting plate **Sta**



## PPCSS

## Stainless steel

- Screwed mounting plate

- Material:

316 stainless steel

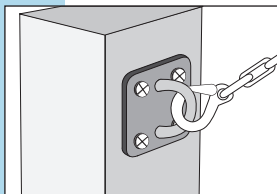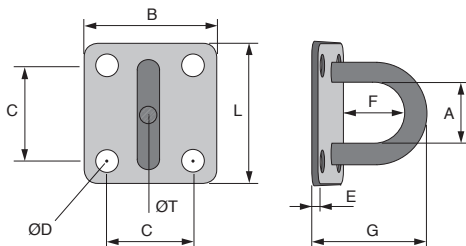

Typical application

### DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	ØD	C	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPC5-16/SS	5	16	30	35	5	19	2,8	15	23	0,027	-	3,75 €
PPC6-20/SS	6	20	35	40	5,5	24	2,8	17	26	0,040	✓	5,02 €
PPC8-23/SS	8	23	40	50	5,5	29	2,8	21	32	0,068	✓	7,80 €

Dimensions in mm

## Our other products



PPOss  
Pad eye on mounting plate, Stainless steel



WINGbrEcrou  
Manually tightened wing nut, Brass DIN 315



CHALss  
Piano hinge, Stainless steel



SLBS  
Indexing plunger, Stainless steel



ACM\_AZ  
Manual bonnet fastener, Hook



KBS\_UU  
Linear bearing, Precision - stainless steel / -20°C +80°C



PRF\_GAL  
Roller for aluminium profile, Fixing kit for roller concentric



TCL-PD  
T-Clip - Aluminium profile attachment, Document holder



PWDL\_PWGDL1  
Worm - precision range, Peek



QTC  
Clip on Quarter turn latch, Slotted head




PX  
Worm and wheel gearbox, P gearboxes single sided output



VELM6  
Screw-on for hook-and-loop, Polyamide
 
## Complementary products



CAB  
Aircraft cable, Stainless steel



MACss  
Carabiner, Stainless steel



SCA\_SS  
Cable clamp, Stainless steel



TAC\_SS  
Rigging screw, Stainless steel