

Indexing pin for sheet metal

Stock

PPD

For thin sheets or walls

- With or without possibility to lock in open position

- Material:


Polyamide knurled knob,

mat surface finish

Body: Chromed steel


Pin: stainless steel

Position of thin wall

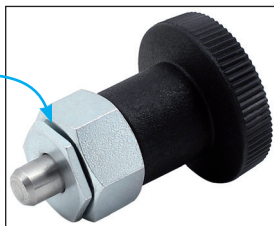


Info.

- Locking version: pull and turn to lock.

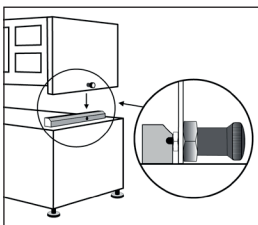

Typical application:
locking

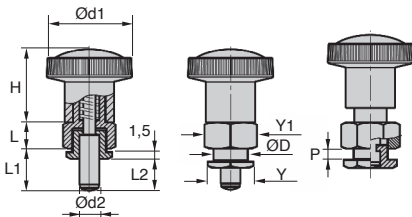

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	Ød1	Ød2	L	H	L1	L2	ØD	Y	Y1	P	Weight (g)	Price each	
												Stock*	1 to 5
Non-locking													
PPD6-8	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10	32	8	8	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	✓	26,97 €
PPD8-12	32	8	8	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €
Locking													
PPD6-8/A	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10/A	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10/A	32	8	10	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	-	26,97 €
PPD8-12/A	32	8	10	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



HG5-ECO

Eco range Spur gear,
Steel C45



HSE-HSB

Hexagonal spacer,
Steel



M0

Worm and wheel set,
Hardened steel



SHS

Shoulder screw
stainless steel 303,
Stainless steel 303



BTE

Universal tension arm,
For normal
applications



DCA

Suction cup, 1.5
bellows, silicon



PO

Pull handle - Multi-
sector, Tapped
recessed insert



SPIT

Floor mounting
levelling plate, With
anchoring point



DEP

Tools Hygienic Usit®
and Hygienic




NPTF30

Spacer for tube
carrier, Fixing



RBNpl

 Swivel castor with
double brake, Steel -



TBV

Manual lifting tables,
20kg

Complementary products



PPF

Indexing plunger with
flange, with drilled
flange



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



BIM

Indexing plunger mini,
miniature