

Indexing pin for sheet metal

Stock

PPD

For thin sheets or walls

- With or without possibility to lock in open position

- Material:


Polyamide knurled knob,

matt surface finish

Body: Chromed steel


Pin: stainless steel

Position of thin wall

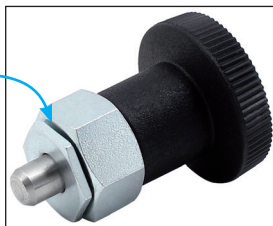


Info.

- Locking version: pull and turn to lock.

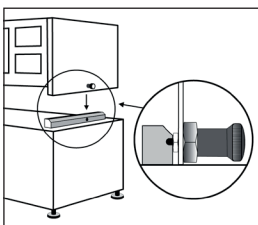

Typical application:
locking

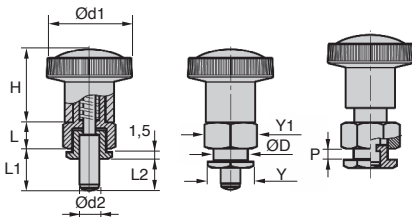

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	Ød1	Ød2	L	H	L1	L2	ØD	Y	Y1	P	Weight (g)	Price each	
												Stock*	1 to 5
Non-locking													
PPD6-8	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10	32	8	8	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	✓	26,97 €
PPD8-12	32	8	8	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €
Locking													
PPD6-8/A	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10/A	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10/A	32	8	10	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	-	26,97 €
PPD8-12/A	32	8	10	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

 
www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



V3RA_PTR
3-spoked handwheel
with foldable handle,
Polyamide



PRF45 GOU
Chute profile,
Accessories



P20
Worm and wheel gear
reducer, up to 5 Nm



T2
T type timing belt,
T2.5 Steel cored
polyurethane



PWC
Powercoil thread
inserts, Kit Powercoil -
with or without
insertion ...



RTT
Locking Assembly,
Medium/high torque



DOMI30
Connecting kits, XZ
linking kit



PR105
Articulated foot Ø103,
Ø 103




SER69K
Quarter turn latch for
the food industry,



DKN
Bellows coupling
Gerwah®, from 0.4 to



 SDG
Adjustable guide
support bracket,



TBV
Manual lifting tables,
20kg

Complementary products



PPF
Indexing plunger with
flange, with drilled
flange



BIMSS
Indexing plunger mini,
miniature - Stainless
steel



BIM
Indexing plunger mini,
miniature