

Indexing pin for sheet metal

Stock

PPD


For thin sheets or walls

- With or without possibility to lock in open position

- Material:


Polyamide knurled knob,
matt surface finish
Body: Chromed steel
Pin: stainless steel

Position of thin wall

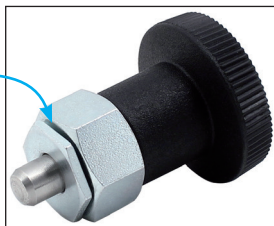


Info.

- Locking version: pull and turn to lock.

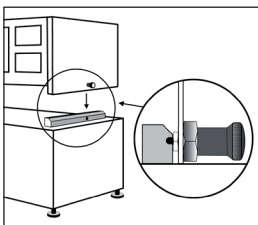

Typical application:
locking

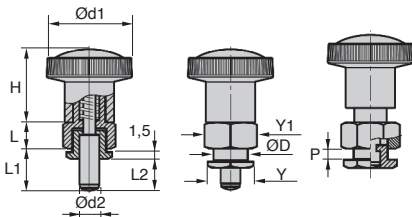

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	Ød1	Ød2	L	H	L1	L2	ØD	Y	Y1	P	Weight (g)	Price each	
												Stock*	1 to 5
Non-locking													
PPD6-8	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10	32	8	8	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	✓	26,97 €
PPD8-12	32	8	8	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €
Locking													
PPD6-8/A	26	6	9	23	8,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD6-10/A	26	6	9	23	10,5	6,0	10x1,0	14	16	from 1 to 5	40	✓	24,52 €
PPD8-10/A	32	8	10	28	10,0	7,5	12x1,5	16	18	from 1 to 5	62	-	26,97 €
PPD8-12/A	32	8	10	28	12,0	7,5	12x1,5	16	18	from 1 to 5	65	✓	26,97 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHAR7520

Spring hinge, screwed



DKGS

Backlash free coupling Gerwah®, from 0.5 to 3Nm



NPCR

Adjustable cell support, Adjustable



UGCG

Actuator guide kit, Long housing



 
MDR

Dee shackle with eye bolt, Steel



BFD

Locking pin for bush, +180°C




PX_PO

Carrying handle, back-plated



BSM_LOK

 Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



CFC

Spring loaded position switch, Electric



RBNpl

Fixed castor with plate, Steel - rubber



PDD

Spring plunger, With sensor adaptor



PHTss

Pull handle, Up to 250 °C

Complementary products



PPF

Indexing plunger with flange, with drilled flange



BIMSS

Indexing plunger mini, miniature - Stainless steel



BIM

Indexing plunger mini, miniature