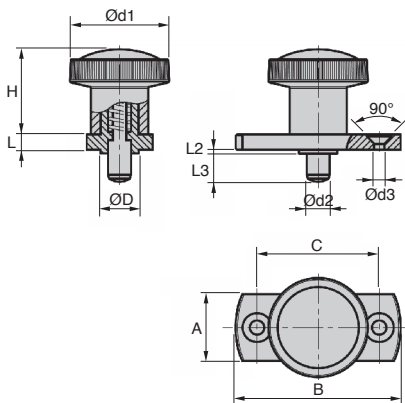


- With or without possibility to lock in open position
- Material:
Polyamide knurled head with matt finish
Flange: Plated steel
Pin: Stainless steel

Info.

- Locking version: pull and turn to lock

**DISCOUNTS**

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Ød1	Ød2	L	H	L3	ØD	L2	A	B	C	Ød3	Weight (g)	Stock*	Price each 1 to 5
Non-locking														
PPF6-6	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	39,04 €
PPF6-14	26	6	5	23	14	10	2	16	42	30	4,30	41,9	✓	39,04 €
PPF8-8	32	8	6	28	8	12	2	20	50	34	5,30	71,4	✓	42,99 €
PPF8-18	32	8	6	28	18	12	2	20	50	34	5,30	74,4	✓	42,99 €
Locking														
PPF6-6/A	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	37,51 €
PPF6-14/A	26	6	5	23	14	10	2	16	42	30	4,30	42,9	✓	37,51 €
PPF8-8/A	32	8	6	28	8	12	2	20	50	34	5,30	72,4	-	41,29 €
PPF8-18/A	32	8	6	28	18	12	2	20	50	34	5,30	73,4	✓	41,29 €

*Subject to availability - Dimensions in mm

Our other products



BAC105

Storage bin, 8mm



M2

Worm and wheel set,
Unhardened steel



BIM

Indexing plunger mini,
miniature



KB_UU

Closed linear
precision bearing,
Precision - steel



BL15

Right angled gearbox,
from 1.10 to 6 Nm



EMR

Fast-locking knurled
nut, Knurled



NPTF30

Fixed tube carrier,
Fixed Ø14 to Ø20



YG1

HEAVY DUTY spur
gear, Steel 35NCD6



Q6

Deep groove ball
bearing, Steel



PPD

Indexing plunger for
sheets, For sheet
metal



GE_ES

Spherical bushing,
Steel / steel



NSP

Right angled support
clamp, Right angled
support clamp

Complementary products



PPD

Indexing plunger for
sheets, For sheet
metal



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



BIM

Indexing plunger mini,
miniature