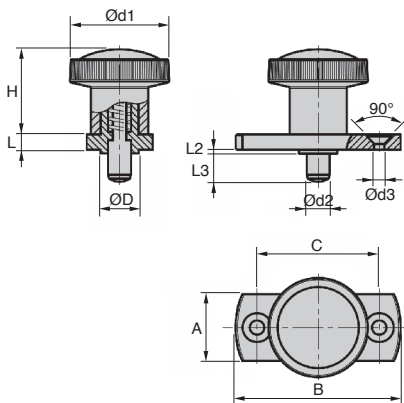


- With or without possibility to lock in open position
- Material:
Polyamide knurled head with matt finish
Flange: Plated steel
Pin: Stainless steel

Info.

- Locking version: pull and turn to lock

**DISCOUNTS**

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Ød1	Ød2	L	H	L3	ØD	L2	A	B	C	Ød3	Weight (g)	Stock*	Price each 1 to 5
Non-locking														
PPF6-6	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	39,04 €
PPF6-14	26	6	5	23	14	10	2	16	42	30	4,30	41,9	✓	39,04 €
PPF8-8	32	8	6	28	8	12	2	20	50	34	5,30	71,4	✓	42,99 €
PPF8-18	32	8	6	28	18	12	2	20	50	34	5,30	74,4	✓	42,99 €
Locking														
PPF6-6/A	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	37,51 €
PPF6-14/A	26	6	5	23	14	10	2	16	42	30	4,30	42,9	✓	37,51 €
PPF8-8/A	32	8	6	28	8	12	2	20	50	34	5,30	72,4	-	41,29 €
PPF8-18/A	32	8	6	28	18	12	2	20	50	34	5,30	73,4	✓	41,29 €

*Subject to availability - Dimensions in mm

Our other products




PF55

Worm and wheel gear reducer, up to 57 Nm



ZDB

Machined plastic bevel gear , 2:1

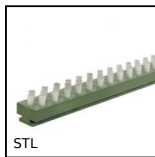


STL

Guidance brush - Brush, Brush



LRX

 Linear roller slide, Rail - from 9410 N to 101000 N



ZR

Plastic rack, Delrin



ADL_F

Female eye bolt conforms to DIN582, Steel



PRFRTR

Cross connector for aluminium profile, Cross connector



HLC28

Right angle spiro bevel gearbox, Up to 182Nm



HRV

V-rail guidance Simple Select® system, Rail with



BEK

Bearing housing for miniature ballscrew, Bearing housing



YG2

HEAVY DUTY spur gear, Steel 35NCD6



RPP

Connecting plate for RPP type timing belts, RPP8

Complementary products



PPD

Indexing plunger for sheets, For sheet metal



BIMSS

Indexing plunger mini, miniature - Stainless steel



BIM

Indexing plunger mini, miniature