


- With or without possibility to lock in open position
- Material:
Polyamide knurled head with matt finish
Flange: Plated steel
Pin: Stainless steel

Info.

- Locking version: pull and turn to lock

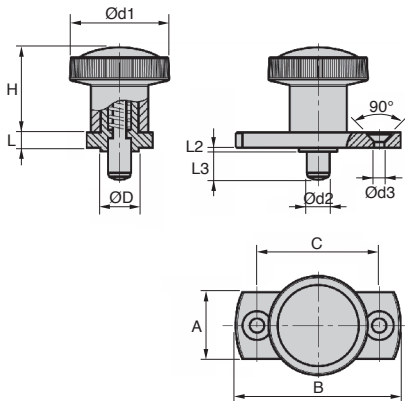

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Ød1	Ød2	L	H	L3	ØD	L2	A	B	C	Ød3	Weight (g)	Stock*	Price each 1 to 5
Non-locking														
PPF6-6	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	39,04 €
PPF6-14	26	6	5	23	14	10	2	16	42	30	4,30	41,9	✓	39,04 €
PPF8-8	32	8	6	28	8	12	2	20	50	34	5,30	71,4	✓	42,99 €
PPF8-18	32	8	6	28	18	12	2	20	50	34	5,30	74,4	✓	42,99 €
Locking														
PPF6-6/A	26	6	5	23	6	10	2	16	42	30	4,30	40,9	✓	37,51 €
PPF6-14/A	26	6	5	23	14	10	2	16	42	30	4,30	42,9	✓	37,51 €
PPF8-8/A	32	8	6	28	8	12	2	20	50	34	5,30	72,4	-	41,29 €
PPF8-18/A	32	8	6	28	18	12	2	20	50	34	5,30	73,4	✓	41,29 €


*Subject to availability - Dimensions in mm

Our other products




GPB55

 Threaded spherical knob, Aluminium



GMC

 Flat profile - Round guide, Flat profile - round guide




ZR

Plastic rack, Delrin




PTA80

 Articulated levelling foot, pressed base Ø80, Ø 80



KGS

 Ballscrew, supplied by the metre, Rolled ballscrew, per metre




RPP8

RPP heavy duty timing belt, RPP8



FF40

 Offset spur gear reducer, from 59 to 210 Nm



PX_PO

Carrying handle, standard



PPF

Indexing plunger with flange, with drilled flange



G2

Steel spur gear, Steel 20NCD2



BSCf

Knurled torque knobs - female, Knurled threaded torque



BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53

Complementary products



PPD

Indexing plunger for sheets, For sheet metal



BIMSS

Indexing plunger mini, miniature - Stainless steel



BIM

Indexing plunger mini, miniature