

# Index plunger with pull ring

## PPJ

### With horizontal flange

- **Mounting flange with screw holes**

- **Materials:**

Body: Zamak with black plastic coating



Pin: Stainless steel 1.4305

Pull ring: Stainless steel 1.4305

- **Working temp range:** -30 /+100 °C

### Info

- Thanks to the pull ring, it is possible to automate the index plunger with, for example, a pneumatic actuator or remote control

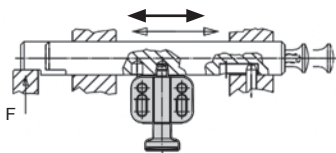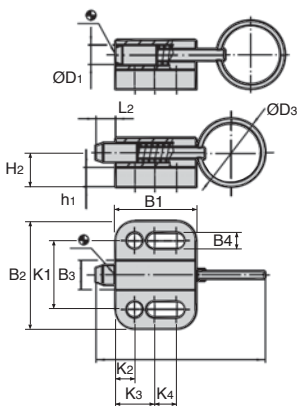

Typical application

### DISCOUNTS

| Qty        | 1+  | 6+   | 20+        | 50+ |
|------------|-----|------|------------|-----|
| Disc. List | -5% | -10% | On request |     |

| Part number | Locking | ØD1 | ØD3 | B1   | B2 | B3 | B4 (-0,2) | h1  | h2   |
|-------------|---------|-----|-----|------|----|----|-----------|-----|------|
| PPJ4-16-22  | Without | 4   | 14  | 16,5 | 22 | 6  | 3,3       | 4   | 7    |
| PPJ5-22-28  | Without | 5   | 18  | 22   | 28 | 8  | 4,3       | 4,5 | 9,5  |
| PPJ6-27-32  | Without | 6   | 24  | 27,5 | 32 | 10 | 5,4       | 5   | 10,5 |
| PPJ8-33-34  | Without | 8   | 30  | 33   | 34 | 12 | 5,4       | 6   | 12,5 |

| Part number | K1 (+/-0,05) | K2  | K3 | K4   | L1   | L2 | Pressure F1 (N) | Pressure F2 (N) | Weight (g) | Price each 1 to 5 |
|-------------|--------------|-----|----|------|------|----|-----------------|-----------------|------------|-------------------|
| PPJ4-16-22  | 14           | 4   | 8  | 4,5  | 34,5 | 4  | 3               | 12              | 10         | 7,06 €            |
| PPJ5-22-28  | 18           | 5   | 10 | 7    | 45   | 5  | 5               | 24              | 20         | 7,36 €            |
| PPJ6-27-32  | 21           | 5,5 | 12 | 10   | 57,5 | 6  | 5               | 21              | 40         | 8,28 €            |
| PPJ8-33-34  | 23           | 5,5 | 12 | 15,5 | 71   | 8  | 6               | 22              | 58         | 8,93 €            |

Dimensions in mm

## Our other products



LVT

Miniature motorised actuator 1A, 1 ampere



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



CHB

Reaction arm, CHB gear reducers reaction arm



PRF-GPA

Guide for aluminium profile, Parallel rails



RPCplss

Swivel castor with plate, Stainless steel - Polyamide



PRF\_PA

Angle plate for aluminium profile, Adjustable plate




CFF

Female rod ends DIN ISO12240-4, Steel / bronze



RFV50

 Stainless steel worm and wheel gearbox, up to 80 Nm



PRF\_CHA D

Hinge and joint, Lift-off hinge



LVT

Miniature motorised actuator 4A, 4 ampere



CHAGC-AL

Screw-in garnet hinge, Screw-on



MACss

Stainless steel carabiner, Stainless steel

## Complementary products



PPG

Indexing plunger with flange, With horizontal mounting flange



SLBW

Indexing plunger, weldable, Weldable - Steel