

# Index plunger with pull ring

## PPJ

### With horizontal flange

- **Mounting flange with screw holes**

- **Materials:**

Body: Zamak with black plastic coating



Pin: Stainless steel 1.4305

Pull ring: Stainless steel 1.4305

- **Working temp range:** -30 /+100 °C

### Info

- Thanks to the pull ring, it is possible to automate the index plunger with, for example, a pneumatic actuator or remote control

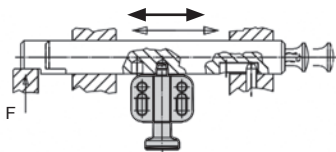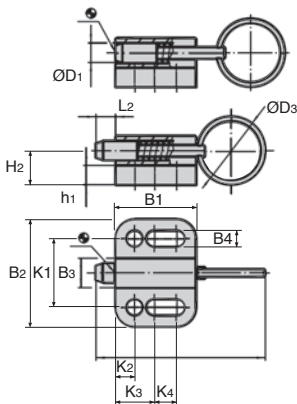

Typical application

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Locking	ØD1	ØD3	B1	B2	B3	B4 (-0,2)	h1	h2
PPJ4-16-22	Without	4	14	16,5	22	6	3,3	4	7
PPJ5-22-28	Without	5	18	22	28	8	4,3	4,5	9,5
PPJ6-27-32	Without	6	24	27,5	32	10	5,4	5	10,5
PPJ8-33-34	Without	8	30	33	34	12	5,4	6	12,5

Part number	K1 (+/-0,05)	K2	K3	K4	L1	L2	Pressure F1 (N)	Pressure F2 (N)	Weight (g)	Price each 1 to 5
PPJ4-16-22	14	4	8	4,5	34,5	4	3	12	10	7,06 €
PPJ5-22-28	18	5	10	7	45	5	5	24	20	7,36 €
PPJ6-27-32	21	5,5	12	10	57,5	6	5	21	40	8,28 €
PPJ8-33-34	23	5,5	12	15,5	71	8	6	22	58	8,93 €

Dimensions in mm

## Our other products



PRF\_BR  
Clamp for aluminium profile, Clamp for profile



PM2  
Worm and wheel set, Bronze



HD  
Double needle roller universal joint, Heavy duty



BRI  
Panel holder, Panel holder



PW\_PWG15  
Wheel - precision range, Bronze



AC156-157  
Strike for toggle latch, 25.5mm



SHSS  
Shoulder screw stainless steel 416, Pre-treated 416 stainless steel




SH1  
Parallel axis helical gear, Steel 20NCD2



OP3\_14\_06  
Reducing sleeve for OP indicators, Reduction socket



TSP\_T10P  
Connecting plate for T type timing belts, T10

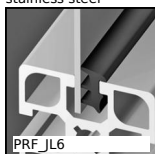

PRF\_JL6  
Lip seal for panel, Door seal - Ø 6mm



HBM  
Adjustment bushing for half-rail guide, Adjustment bushing

## Complementary products



PPG  
Indexing plunger with flange, With horizontal mounting flange



SLBW  
Indexing plunger, weldable, Weldable - Steel