

Pad eye on oval mounting plate

Sta


PPOSS

Stainless steel


- Screwed mounting plate

- Material:

316 stainless steel

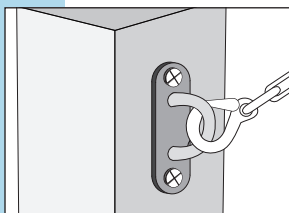

Typical application

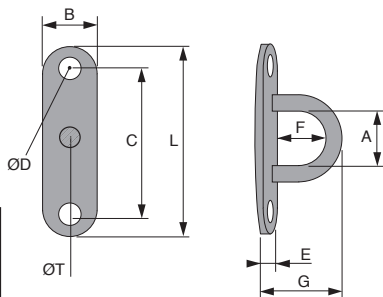


DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPO5-14/SS	5	14	15	45	35	4,5	2,8	13	21	0,019	✓	3,10 €
PPO6-16/SS	6	16	20	60	45	5	2,8	15	25	0,040	✓	4,80 €
PPO8-20/SS	8	20	26	80	60	5,5	2,8	23	33	0,065	✓	7,90 €

Dimensions in mm

 Our other products



PO

Pull handle - Multi-sector, Smooth hole



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



M2

Worm and wheel set, Machined plastic (delrin)



ESCON

Speed controller 5A accessories, Kit of 4 cables for DC motor



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



NIN

Self-locking nut, A2 Stainless steel



NCT

Square tube connector, Fixed angle




PRF_RR

Coupling bar for aluminium profile, Coupling bar



NT91

 Spur gear coaxial gearbox, from 10 to 5000 rpm



NRR

Adjustable support clamp, Adjustable



ARTE

Flexible bush, For multi-directional loads



R204

Die spring ISO10243, Average

Complementary products



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



MRA_SS

Stainless steel Quick link, Stainless steel



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



MACss

Stainless steel carabiner, Stainless steel