

Pad eye on oval mounting plate

Sta


PPOSS

Stainless steel


- Screwed mounting plate

- Material:

316 stainless steel

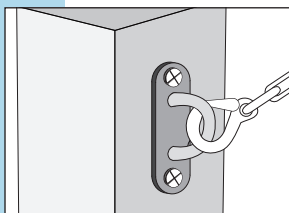

Typical application

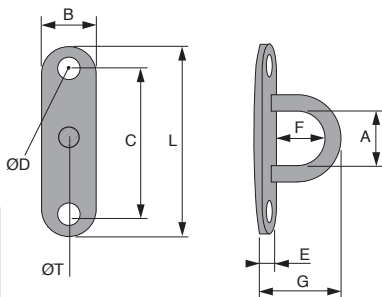

DISCOUNTS

| | | | | | | |
|------|------|-----|------|------|------|------------|
| Qty | 1+ | 20+ | 40+ | 60+ | 80+ | 100+ |
| Disc | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØT | A | B | L | C | ØD | E | F | G | Weight (kg) | Stock* | Price each 1 to 19 |
|-------------|----|----|----|----|----|-----|-----|----|----|-------------|--------|--------------------|
| PPO5-14/SS | 5 | 14 | 15 | 45 | 35 | 4,5 | 2,8 | 13 | 21 | 0,019 | ✓ | 3,10 € |
| PPO6-16/SS | 6 | 16 | 20 | 60 | 45 | 5 | 2,8 | 15 | 25 | 0,040 | ✓ | 4,80 € |
| PPO8-20/SS | 8 | 20 | 26 | 80 | 60 | 5,5 | 2,8 | 23 | 33 | 0,065 | ✓ | 7,90 € |

Dimensions in mm

Our other products



RMSA

Adjustable shock absorber, Adjustable



MRAeco

Low cost quick link, Steel



 
SFWR

End support, Surface mounting



ACA

Steel splined shaft, Steel



LAT1

1A motorised linear actuator, 1 ampere



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm



GP

Spring loaded toggle latch, With padlock holder



SBRtool

Chain tool, Drive chain maintenance tools



HTD5M_25

HTD Heavy duty timing pulley, HTD5 Steel



DBL880

Idler for slat top chain, Ranges 880 and 881



NSU

Universal 90° support clamp, Universal 90° support clamp



M0

Worm and wheel set, Machined plastic (delrin)

Complementary products



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



MRA_SS

Stainless steel Quick link, Stainless steel



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



MACss

Stainless steel carabiner, Stainless steel