

Pad eye on oval mounting plate

Sta


PPOSS

Stainless steel


- Screwed mounting plate

- Material:

316 stainless steel

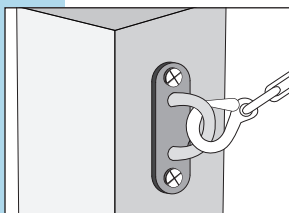

Typical application

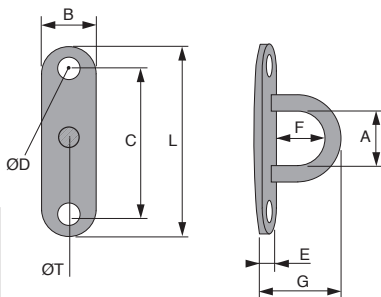

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPO5-14/SS	5	14	15	45	35	4,5	2,8	13	21	0,019	✓	3,10 €
PPO6-16/SS	6	16	20	60	45	5	2,8	15	25	0,040	✓	4,80 €
PPO8-20/SS	8	20	26	80	60	5,5	2,8	23	33	0,065	✓	7,90 €

Dimensions in mm

Our other products



RCX-6

Spherical tilt washer -
DIN6319, concave



VTH

Hexagonal headed
bolts, Steel class 8.8



GARDLL

Mounting sleeve for
lock pin, Nickel-plated
steel or Stainless steel



 
H2

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



BPL

Ball transfer unit light
duty, Light



KS

Keysteel, Stainless
steel - Keystock



BPM

Slotted spring plunger
with ball tip, Steel



PP60

Worm and wheel gear
reducer, from 17.80
to 34 Nm



SSG0

Stainless steel spur
gear, Stainless steel



VTLM

3 lobed handle,
Polyamide - Steel



Gal-cardan

Single universal joint
eco series, Low duty



MFB_MHB

Moulded plastic bevel
gear (nylon), 4:1

Complementary products



TCC_SS

Stainless steel rigging
screw (hook/hook),
Stainless steel



MRA_SS

Stainless steel Quick
link, Stainless steel



CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel



MACss

Stainless steel
carabiner, Stainless
steel