

Pad eye on oval mounting plate

Sta


PPOSS

Stainless steel


- Screwed mounting plate

- Material:

316 stainless steel

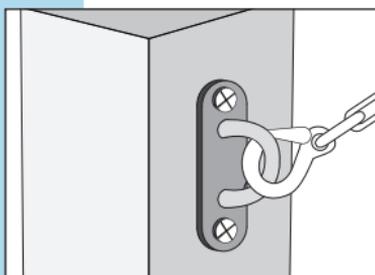

Typical application

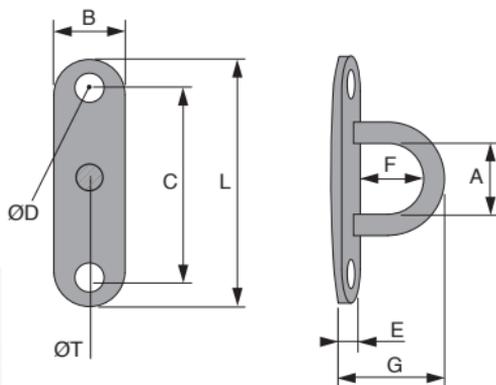

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	B	L	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPO5-14/SS	5	14	15	45	35	4,5	2,8	13	21	0,019	✓	3,10 €
PPO6-16/SS	6	16	20	60	45	5	2,8	15	25	0,040	✓	4,80 €
PPO8-20/SS	8	20	26	80	60	5,5	2,8	23	33	0,065	✓	7,90 €

Dimensions in mm

Our other products



S_ZZ

Deep groove ball bearing, Stainless steel




FBL6000_K1

Brush strip per meter PA6 fibres Ø0.2 to Ø0.3, Black polyamide 6-...



GET-AL

Jaw coupling, economy range, Aluminium

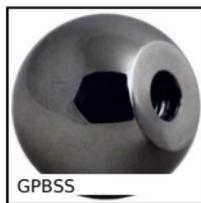

GPBSS

Threaded spherical knob, Aluminium



RDS

Safety washer Hygienic Usit®, Stainless steel



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket



RESC

Retractable castor for aluminium profile, Retractable castor



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



G2

Steel spur gear, Steel 20NCD2



S2B

Short linear bearing housing, Closed - Slim



BLH60

Right angled gearbox, from 19 to 70 Nm



VRBS

Folding lifting ring for welding, Folding - for welding

Complementary products



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



MRA_SS

Stainless steel Quick link, Stainless steel



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



MACss

Stainless steel carabiner, Stainless steel