
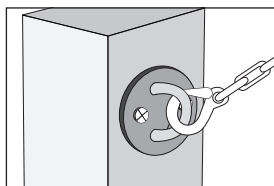


- Screwed mounting plate
- Material:
316 stainless steel

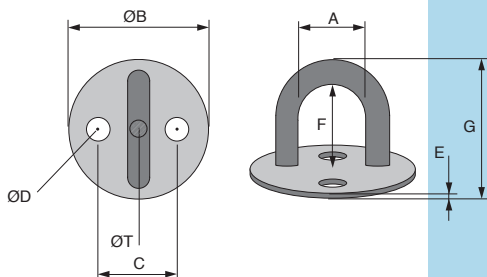

Typical application

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	ØB	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPR5-13/SS	5	13	33	20	4	2,8	13	21	0,023	✓	3,72 €
PPR6-17/SS	6	17	40	23	4,5	2,8	17	26	0,030	✓	5,35 €
PPR8-20/SS	8	20	50	29	5	2,8	22	33	0,068	-	8,47 €


Dimensions in mm

Fax **0 825 88 6000**
Service 0,15 € / min
+ prix appel

Our other products



 DOMI120
Connecting kits, XZ
linking kit



H1
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



PCP
Cell carrier assembly,
Ready assembled



HG5
Steel spur gear, Steel
20NCD2



DILC
Indexing plunger with
cam, with cam



G2
Steel spur gear, Steel
20NCD2



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



SSDB
Stainless steel bevel
gear, 2:1



DOMI30
Domino 30 adjustable
slide, Slide DOMILINE
30



VPPTss
Stainless steel
handwheel with
handle, Stainless steel




PENC
Recessed handle, clip-
in



ZG2
Plastic spur gear,
Machined plastic
(delrin)

 Complementary products



CAB
Stainless steel cable,
Stainless steel



SCA_SS
Stainless steel flat
cable clamp, Stainless
steel



MACss
Stainless steel
carabiner, Stainless
steel



CHN_CHNSS
Straight long link
stainless steel chain,
Stainless steel