
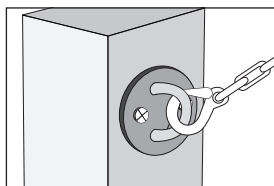


- Screwed mounting plate
- Material:
316 stainless steel

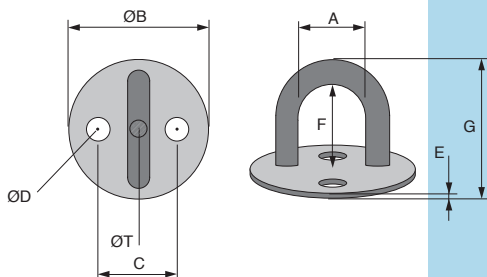

Typical application

DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	ØB	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPR5-13/SS	5	13	33	20	4	2,8	13	21	0,023	✓	3,72 €
PPR6-17/SS	6	17	40	23	4,5	2,8	17	26	0,030	✓	5,35 €
PPR8-20/SS	8	20	50	29	5	2,8	22	33	0,068	-	8,47 €

Dimensions in mm

Fax **0 825 88 6000**
Service 0,15 € / min
+ prix appel

Our other products



GB-RA

Brass spur gear, Brass
CuZn39Pb3



BAC110

Swivel storage bin,
Adjustable support



AT5P_AT10P

Connecting plate for
AT type timing belts,
AT5




LSAG

Sleeve for splined ball
shaft, Chariot - from
514 N to 15386 N



NPTR10

Adjustable cross
clamp, Adjustable

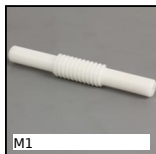

M1

Worm and wheel set,
Machined plastic
(delrin)



NCT

Square tube
connector, Fixed
angle



BOX-TOR-C

Box set of Nitrile O-rings
in nitrile, 3.00 x
1.50mm to 30.20 x
3.00



H0

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



GLB

Small 6 lobe female
handle,
Technopolymer -



RVM25

 
Manually operated
gearbox, Bevel



FBL6000_K19

Brush strip per meter
horsehair fibres Ø0.2,
Black horsehair

Complementary products



CAB

Stainless steel cable,
Stainless steel



SCA_SS

Stainless steel flat
cable clamp, Stainless
steel



MACss

Stainless steel
carabiner, Stainless
steel



CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel