
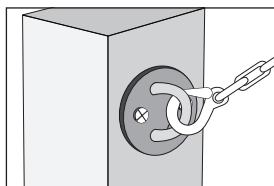


- Screwed mounting plate
- Material:  
316 stainless steel

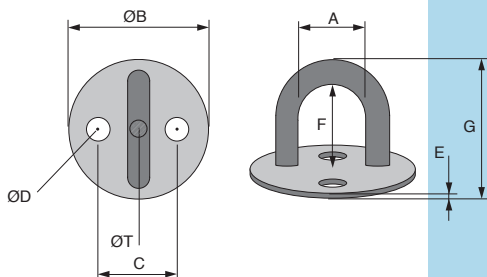

Typical application

## DISCOUNTS

|       |      |     |      |      |      |            |
|-------|------|-----|------|------|------|------------|
| Qty   | 1+   | 20+ | 40+  | 60+  | 80+  | 100+       |
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØT | A  | ØB | C  | ØD  | E   | F  | G  | Weight (kg) | Stock* | Price each 1 to 19 |
|-------------|----|----|----|----|-----|-----|----|----|-------------|--------|--------------------|
| PPR5-13/SS  | 5  | 13 | 33 | 20 | 4   | 2,8 | 13 | 21 | 0,023       | ✓      | 3,72 €             |
| PPR6-17/SS  | 6  | 17 | 40 | 23 | 4,5 | 2,8 | 17 | 26 | 0,030       | ✓      | 5,35 €             |
| PPR8-20/SS  | 8  | 20 | 50 | 29 | 5   | 2,8 | 22 | 33 | 0,068       | -      | 8,47 €             |

Dimensions in mm

Fax **0 825 88 6000**  
Service 0,15 €/min  
+ prix appel

## Our other products



PLA

Flat magnet, Flat magnet with thread



RFVcap

Stainless steel protective cover, Open protective cover



GE1006

Elastic ringed latch, Hooks into a slot



BOX-CS

Hose clamp, Box set of steel hose clamps



AC

Strike for toggle latch, 15mm



METEB

Self-lubricating blanks, Ferrous alloy (FP20)



SLB

Indexing plunger, stainless steel



PCF2

Conical flexible mount, Oval base plate



DOMI30

Accessories, Fixing kit



PM2

Worm and wheel set, Hardened steel



TB\_ECO


Eco. range steel bevel gear, 3:1



DIV\_SS

Stainless steel locking bolt, With grip - Stainless steel

## Complementary products

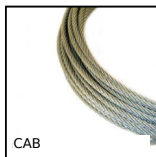

CAB

Stainless steel cable, Stainless steel



SCA\_SS

Stainless steel flat cable clamp, Stainless steel



MACss

Stainless steel carabiner, Stainless steel



CHN\_CHNSS

Straight long link stainless steel chain, Stainless steel