
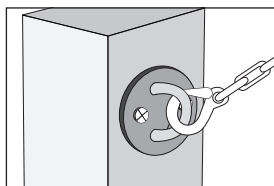


- Screwed mounting plate
- Material:  
316 stainless steel

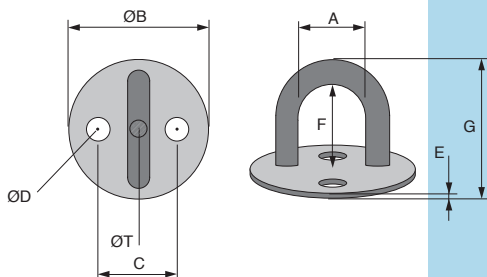

Typical application

## DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØT	A	ØB	C	ØD	E	F	G	Weight (kg)	Stock*	Price each 1 to 19
PPR5-13/SS	5	13	33	20	4	2,8	13	21	0,023	✓	3,72 €
PPR6-17/SS	6	17	40	23	4,5	2,8	17	26	0,030	✓	5,35 €
PPR8-20/SS	8	20	50	29	5	2,8	22	33	0,068	-	8,47 €

Dimensions in mm

Fax **0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products




PRF4532  
Standard aluminium  
profile, 45 x 32 mm



HRV  
V-rail guidance  
Simple Select®  
system, Rail with  
carriage



 UCP\_PBT  
Stainless/Polymer  
pillow block bearing,  
Polymer and stainless  
steel



CDRs  
Retaining cable for  
ball pin, Retaining  
cable



DOMI30  
Accessories, Turntable



CFF  
Female rod ends DIN  
ISO12240-4, Steel /  
bronze



CHMR50  
Worm and wheel gear  
reducer, up to 107  
Nm



SSDB  
Stainless steel bevel  
gear, 2:1



TBEBASE10  
Economic mini-table  
with trapezoidal



GP75  
Spring loaded toggle  
latch, Standard




DTR  
Chain idler sprocket,  
Chain idler sprocket -



DIA  
Ring operated locking  
bolt, with ring

## Complementary products

 

CAB  
Stainless steel cable,  
Stainless steel



SCA\_SS  
Stainless steel flat  
cable clamp, Stainless  
steel



MACss  
Stainless steel  
carabiner, Stainless  
steel



CHN\_CHNSS  
Straight long link  
stainless steel chain,  
Stainless steel