


- **Levelling foot**
- Non slip base
- **Materials:**
 - Base: Black glass reinforced polyamide (Shore 70)
 - Spindle: Zinc plated steel or stainless 304 (nut not supplied)

Info.

- Values given for static loads will be reduced in case of a vibrating load

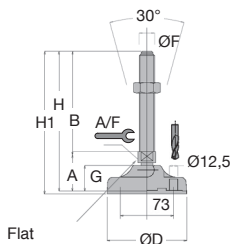

DISCOUNTS

Qty	1+	20+	50+
Disc.	List -10%	On request	

Part number	ØD	Thread ØF	B	A	A/F	G	H	H1	Static load (N)	Price each	
										Stock*	1 to 19
Steel spindle											
PR105-16-75	103	M16	75	51	20	32	126	129	25000	✓	17,76 €
PR105-16-150	103	M16	150	51	20	32	201	204	25000	✓	21,36 €
PR105-16-225	103	M16	225	51	20	32	276	279	25000	✓	26,31 €
PR105-20-125	103	M20	125	51	20	32	176	179	25000	✓	17,99 €
PR105-20-200	103	M20	200	51	20	32	251	254	25000	✓	21,34 €
PR105-20-250	103	M20	250	51	20	32	301	304	25000	✓	26,31 €
PR105-24-125	103	M24	125	51	20	32	176	179	25000	✓	17,99 €
PR105-24-200	103	M24	200	51	20	32	251	254	25000	✓	21,34 €
PR105-24-250	103	M24	250	51	20	32	301	304	25000	✓	26,31 €
Stainless steel spindle											
PR105-16-75/SS	103	M16	75	51	20	32	126	129	25000	✓	31,56 €
PR105-16-150/SS	103	M16	150	51	20	32	201	204	25000	✓	41,75 €
PR105-16-225/SS	103	M16	225	51	20	32	276	279	25000	✓	53,74 €
PR105-20-125/SS	103	M20	125	51	20	32	176	179	25000	✓	36,50 €
PR105-20-200/SS	103	M20	200	51	20	32	251	254	25000	✓	50,12 €
PR105-20-250/SS	103	M20	250	51	20	32	301	304	25000	✓	58,20 €
PR105-24-125/SS	103	M24	125	51	20	32	175	178	25000	-	36,50 €
PR105-24-200/SS	103	M24	200	51	20	32	250	253	25000	-	50,12 €
PR105-24-250/SS	103	M24	250	51	20	32	300	303	25000	-	58,20 €

*Depending on availability - Dimensions in mm

Our other products



BUH77
Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm



Q7
Angular contact ball
bearing, Steel



SRG
Adjustable latch
clamp with strike
plate, Stroke from
96mm to 121,7mm



APB_BOU
Protective cap, Safety
cap



ZBconique
Machined plastic
bevel gear, 1:1



HW_HT
Half-rail guide, Wheel



NCT
Square tube
connector, Fixed
angle



SSDB
Stainless steel bevel
gear, 2:1



BLH60
Right angled gearbox,
from 19 to 70 Nm



PGT
Sliding profile, Sliding
panel support



SR
Narrow spur rack,
Stainless steel



STRIPF
Sealing brush strip,
1m length

Complementary products



ES
Support base (tripod),
Plastic



ES
Bipod support base,
Plastic



ES
Simple support base
(bipod), Plastic



PR65C
Half-articulated foot Ø
65, Ø 65