

Fixable articulated foot Ø123

Stock Ste Sta


PR125

Maximum load 35,000N

- Levelling foot
- Non slip base
- Materials:
 Base: Black glass reinforced polyamide (Shore 70)
 Spindle: Zinc plated steel or stainless steel 304 (nut not supplied)

With non-slip base

Steel or stainless steel spindle

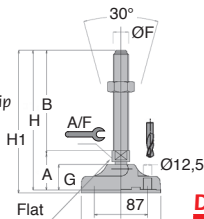

Advantages

- Articulated rod allows auto-alignment with the ground
- Sole material ensures flexibility and grip

Info.

- Values given for static loads will be reduced in case of a vibrating load

DISCOUNTS

Qty	1+	20+	50+
Disc.	List -10%	On request	On request

Part number	ØD	Thread	B	A	A/F	G	H	H1	Static load (N)	Price each	Stock*
Steel spindle											
PR125-16-75	123	M16	75	57	20	37	132	133	35000	20,66 €	✓
PR125-16-150	123	M16	150	57	20	37	207	208	35000	24,30 €	✓
PR125-16-225	123	M16	225	57	20	37	282	285	35000	28,41 €	✓
PR125-20-125	123	M20	125	57	20	37	182	185	35000	20,55 €	✓
PR125-20-200	123	M20	200	57	20	37	257	260	35000	23,99 €	✓
PR125-20-250	123	M20	250	57	20	37	307	310	35000	28,20 €	✓
PR125-24-125	123	M24	125	57	20	37	182	185	35000	20,55 €	✓
PR125-24-200	123	M24	200	57	20	37	257	260	35000	23,99 €	✓
PR125-24-250	123	M24	250	57	20	37	307	310	35000	28,20 €	✓
PR125-30-125	123	M30	125	58	26	37	183	186	35000	22,07 €	✓
PR125-30-200	123	M30	200	58	26	37	258	261	35000	26,40 €	✓
PR125-30-250	123	M30	250	58	26	37	308	311	35000	29,39 €	-
Stainless steel spindle											
PR125-16-75/SS	123	M16	75	57	20	37	132	135	35000	35,62 €	-
PR125-16-150/SS	123	M16	150	57	20	37	207	210	35000	45,76 €	✓
PR125-16-225/SS	123	M16	225	57	20	37	282	285	35000	57,77 €	-
PR125-20-125/SS	123	M20	125	57	20	37	182	185	35000	42,39 €	✓
PR125-20-200/SS	123	M20	200	57	20	37	257	260	35000	54,16 €	✓
PR125-20-250/SS	123	M20	250	57	20	37	307	310	35000	62,27 €	-
PR125-24-125/SS	123	M24	125	57	20	37	182	185	35000	42,39 €	-
PR125-24-200/SS	123	M24	200	57	20	37	257	260	35000	48,31 €	-
PR125-24-250/SS	123	M24	250	57	20	37	307	310	35000	62,27 €	-
PR125-30-125/SS	123	M30	125	58	26	37	183	186	35000	48,10 €	-
PR125-30-200/SS	123	M30	200	58	26	37	258	261	35000	61,41 €	-
PR125-30-250/SS	123	M30	250	58	26	37	308	311	35000	69,98 €	-

*Depending on availability - Dimensions in mm

Our other products



ADL_M

Male eye bolt conforms to DIN580, Steel



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



DER80

Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



HW_HT

Half-rail guide, Rail



RBGtc

Swivel castor with central hole, Steel - grey rubber



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



PSG125

Spur gear - precision range, Case hardened steel 20NCD2



 
NIN

Self-locking nut, Steel



VPRA_M

Handwheel with handle,



NANO

Speed controller 3A, 3 A



RBNpl

Fixed castor with plate, Steel - rubber

Complementary products



ESCB

Combined bipod support base, Bipod support element with cross support



ESSB

Bipod support base, Bipod support base