

Fixable articulated foot Ø40 and Ø50 **Ste****Sta****Stock**

PR40 PR50

Accepts loads up to 11,000N

- Levelling foot
- Rubber anti-slip sole (NBR 70 Shore)
- Black glass fibre reinforced Polyamide base
- Threaded ball ended spindle in plated steel or stainless steel
- Nut not supplied

With non-slip sole


Steel or stainless steel spindle

Advantages

- Self aligning on floor due to use of ball ended rod
- Flexible and non-slip sole

Info.

- If subjected to vibration, the static loads given will be reduced

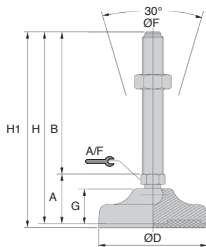

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØD	Thread ØF	B	A	A/F	G	H	H1	Static load (N)	Price each 1 to 19
Steel spindle										
PR40-6-25	40	M6	25	27	12	16,5	52	55	5000	- 5,25 €
PR40-6-50	40	M6	50	27	12	16,5	77	80	5000	- 5,25 €
PR40-8-50	40	M8	50	27	12	16,5	77	80	10000	✓ 5,84 €
PR40-8-100	40	M8	100	27	12	16,5	127	130	10000	✓ 8,09 €
PR50-10-75	50	M10	75	30	14	20,0	105	108	11000	✓ 7,88 €
PR50-10-125	50	M10	125	30	14	20,0	155	158	11000	✓ 9,40 €
PR50-12-75	50	M12	75	30	14	20,0	105	108	11000	✓ 8,64 €
PR50-12-125	50	M12	125	30	14	20,0	155	158	11000	✓ 9,65 €
PR50-16-75	50	M16	75	30	16	20,0	105	108	11000	- 9,75 €
PR50-16-125	50	M16	125	30	16	20,0	155	158	11000	- 10,92 €
Stainless steel spindle										
PR40-6-25/SS	40	M6	25	27	12	16,5	52	55	5000	- 7,93 €
PR40-6-50/SS	40	M6	50	27	12	16,5	77	80	5000	- 10,01 €
PR40-8-50/SS	40	M8	50	27	12	16,5	77	80	10000	✓ 10,94 €
PR40-8-100/SS	40	M8	100	27	12	16,5	127	130	10000	✓ 15,60 €
PR50-10-75/SS	50	M10	75	30	14	20,0	105	108	11000	✓ 14,58 €
PR50-10-125/SS	50	M10	125	30	14	20,0	155	158	11000	✓ 17,95 €
PR50-12-75/SS	50	M12	75	30	14	20,0	105	108	11000	✓ 13,43 €
PR50-12-125/SS	50	M12	125	30	14	20,0	155	158	11000	✓ 16,40 €
PR50-16-75/SS	50	M16	75	30	16	20,0	105	108	11000	- 14,87 €
PR50-16-125/SS	50	M16	125	30	16	20,0	155	158	11000	- 17,49 €

*Depending on availability- Dimensions in mm

Our other products



BUT

Panels accessories,
Panel stop



PTA150

Articulated foot with
pressed base, Ø 150




ADL_F

Eye bolt, Stainless
steel



CHT56

 3 phase AC
asynchronous motor,
0.09kW



PM2

Wheel, Machined
plastic (delrin)



SMS

Spiral bevel gear, 1:1



UTKpwr

Linear motion
Utilitrack®, Polymer
roller carriage



PRF4545

Standard aluminium
profile, 45 x 45 mm



RCX-6

Spherical tilt washer -
DIN 6319, concave



LF

Bearing - accessories,
Precision locknut



ZA

Linear shaft,
Hardened ground
steel



GLB

Small 6 lobe threaded
handle,
Technopolymer -
Stainless steel

Complementary products



ESCB

Support base, Bipod
support element with
cross support



ESSB

Support base, Bipod
support base