



Idler sprocket for plate chain

For chain ranges 820 and 815

PR820

- For use with CAP820 and CAP815 plate chains

- Materials:

Reinforced polyamide

Stainless steel screws


- Operating temp.: -10°C to +120°C

- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

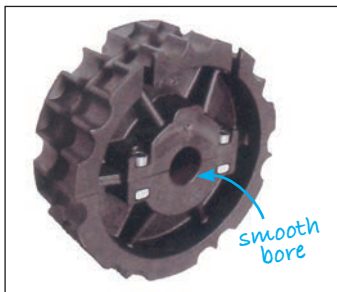

Two part design

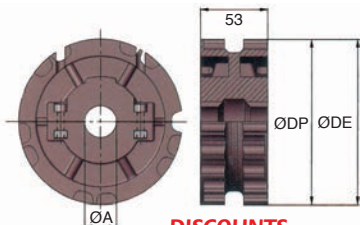

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR820-21-25	21	129	129,26	25	0,4	30,67 €
PR820-21-30	21	129	129,26	30	0,4	30,67 €
PR820-21-35	21	129	129,26	35	0,4	30,67 €
PR820-21-40	21	129	129,26	40	0,4	30,67 €
PR820-21-45	21	129	129,26	45	0,4	30,67 €
PR820-23-25	23	141	141,22	25	0,5	32,38 €
PR820-23-30	23	141	141,22	30	0,5	32,38 €
PR820-23-35	23	141	141,22	35	0,5	32,38 €
PR820-23-40	23	141	141,22	40	0,5	32,38 €
PR820-23-45	23	141	141,22	45	0,5	32,38 €
PR820-25-25	25	153	153,20	25	0,5	32,71 €
PR820-25-30	25	153	153,20	30	0,5	32,71 €
PR820-25-35	25	153	153,20	35	0,5	32,71 €
PR820-25-40	25	153	153,20	40	0,5	32,71 €
PR820-25-45	25	153	153,20	45	0,5	32,71 €

Dimensions in mm

Our other products



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



VELM4

Screw-on base for hook-and-loop strip, Polyamide



PO

Pull handle - Multi-sector, Tapped recessed insert



BTCW

Cap for square tube to be welded, To be welded



SDA

Locking bolt support bracket, Mounting holes parallel to locating bolt



PRF_PGN

Door handle for aluminium profile, Handle with lock suitable



MPS

Hexagonal spacer, Stainless steel 303



EX

Optional shaft for E-type gear reducers, E Gearboxes single sided ou...



 
MPE

Hexagonal spacer, Steel



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



MLY

Bow shackle with eye bolt, Steel



YG2

HEAVY DUTY spur gear, Steel 35NCD6

Complementary products



CAP820

Slim slat top chain acetal, Narrow straight range 820



CAP815

Slim slat top chain stainless steel, Narrow range 815



DBL820

Idler for slat top chain, Ranges 820 and 815



PT820

Drive sprocket for slat top chain, Ranges 820 and 815