



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

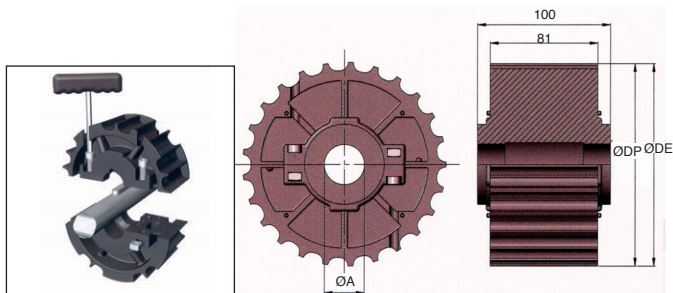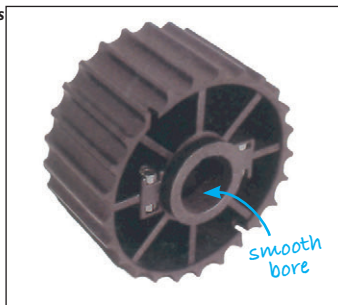

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



EKONSL

Silicone conical elasto buffer, Female mounting



YG0

HEAVY DUTY spur gear, Steel 35NCD6



CLB_M

Die cast zinc clamping lever - female, Zamak



LVT

Miniature motorised actuator 2A, 2 ampers



RPP

Connecting plate for RPP type timing belts, RPP8



 
WTM

Tightening washer - DIN6340, Steel



GTC

Belt tensioner, For standard applications



IN1

Internal gear, Machined plastic (delrin)



NPTF20

Fixed tube carrier, Fixed Ø10 to Ø14



LVT

Miniature motorised actuator 4A, 4 ampers



T2

T type timing belt, T2.5 Steel cored



AZY

Cylindrical elasto mount, Steel

Complementary products