



Idler sprocket for plate chain

For chain ranges 821 and 805


PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

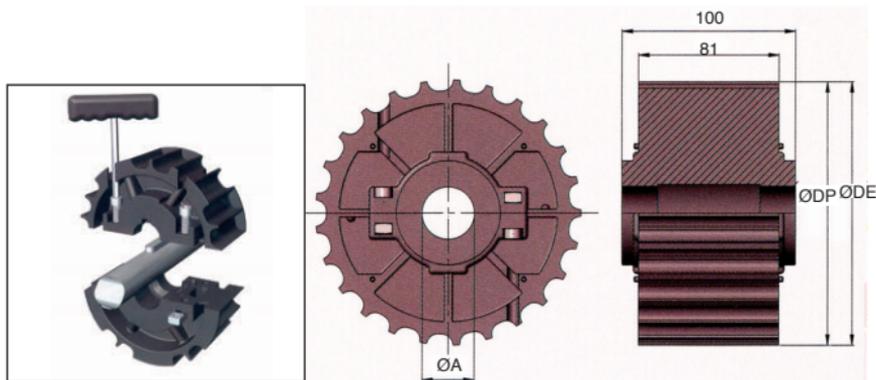

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €


Dimensions in mm

Our other products



CHTRP

Single and dual output gearboxes, Up to 75,7 Nm

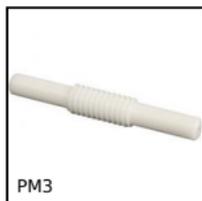

PM3

Worm, Machined plastic (delrin)



RIMple

Locking castor, with mounting plate



CHT

Asynchronous AC motor , 0.09kW



CHT

Asynchronous AC Motor, 0.55 to 1.1kW



PITAss

Locking bolt, with T handle



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



BPHR

Ball transfer unit housed spring loaded, High



TB_ECO

Eco. range steel bevel gear, 3:1



ALIDRP240

24V DC power supply, 10 A



SA_SAKH

Housing for linear bearing, Closed - light



T5P_T10P

Connecting plate for T type timing belts, T10

Complementary products