



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

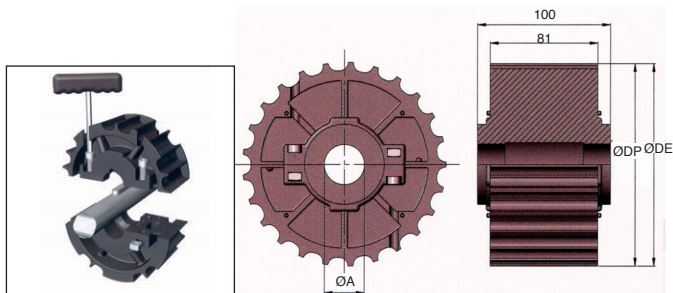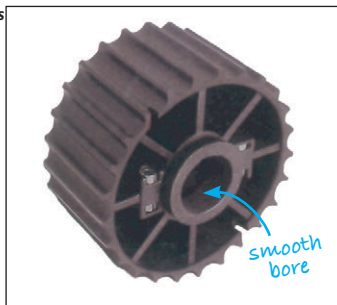

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



BLM
Spring loaded plunger with ball tip, Stainless steel body



PSG05
Spur gear - precision range, Pre-hardened Steel 35NCD6



ERC
Quick fitting cable terminal, Fork




NT92
Spur gear coaxial gearbox, from 15 to 40 Nm - In-line



PM4
Wormwheel, Bronze



 HG8-ECO
Eco range Spur gear, Steel C45



PM3
Wormwheel , Machined plastic (delrin)



PAP
Handle for aluminium profile, Ergonomic handle



BLH60
Right angled gearbox, from 19 to 70 Nm



SA_SAKH
Housing for linear bearing, Closed - light load



GG2
Ground spur gear, Heat treated steel



PCS50K
Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)

Complementary products