



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

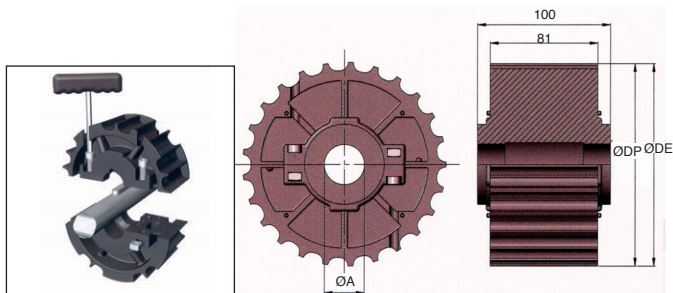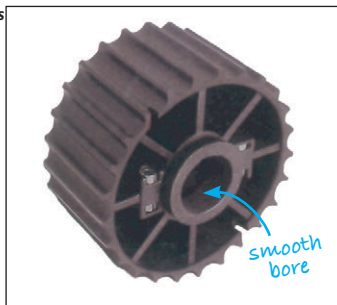

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products




CHAEss

Decorative hinge,
Stainless steel



MSP19

 Masterplate®
glueable insert Ø19,
Cylindrical with
tapped insert



AF

Shaft clamp with
keyway, Set screw



 
PFM

Fixed levelling foot,
Flanged plate



BABreglable

Adjustable ball pin
hardened stainless
steel, adjustable




GCT

Pipe linch pin, Tube
linch pin



R205

Die spring ISO10243,
Heavy

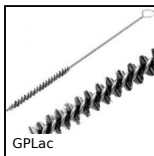

GPLac

Brush, steel



RVM25

Manually operated
gearbox, Bevel



BOXKU

Boxed set of half
round (Woodruff) keys
NFE22179, Boxed set



CHAB

Hinge with stop,
Hinge



VELprf

Clip-on base for hook-
and-loop strip,
Polyamide

Complementary products