



Idler sprocket for plate chain

For chain ranges 821 and 805


PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

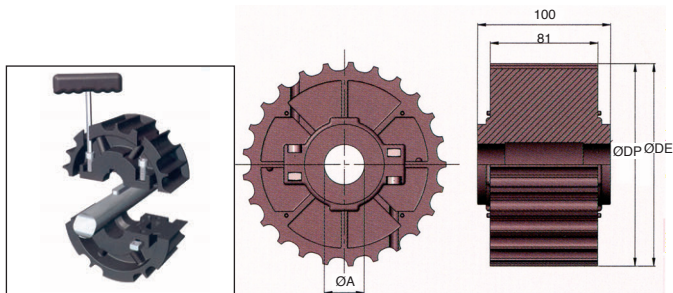

Two part design

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List | -5% | On request |

| Part number | No. of teeth | ØDE | ØDP | Bore ØA | Weight (kg) | Price each 1 to 4 |
|-------------|--------------|-----|-------|---------|-------------|-------------------|
| PR821-25-30 | 25 | 153 | 153,2 | 30 | 0,9 | 70,12 € |
| PR821-25-35 | 25 | 153 | 153,2 | 35 | 0,9 | 70,12 € |
| PR821-25-40 | 25 | 153 | 153,2 | 40 | 0,9 | 70,12 € |
| PR821-25-45 | 25 | 153 | 153,2 | 45 | 0,9 | 70,12 € |

Dimensions in mm

Our other products



OP3_14_06
Reducing sleeve for
OP indicators,
Reduction socket



BPVMss
Stainless steel
miniature ball transfer
unit, Miniature to
screw



HLA28
Right angle spiro
bevel gearbox, Up to
182Nm



CHA138
Screwed hinge with
threaded insert, 138
degrees



LSAG
Sleeve for splined ball
shaft, Chariot - from
514 N to 15386 N



GMK17_R
Round guide, Round
guide for conical
profile



ZAm
Shaft for linear
guides, Hardened
ground steel



DOM120
Accessories, Turntable



DOG258
Motor-gearbox 12V
and 24V DC, from 12



SLBS
Stainless steel
indexing plunger,



PPS
Lifting ring, Universal
threaded



PR125
Articulated foot Ø123,
Ø 123

Complementary products