



Idler sprocket for plate chain

For chain ranges 821 and 805


PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

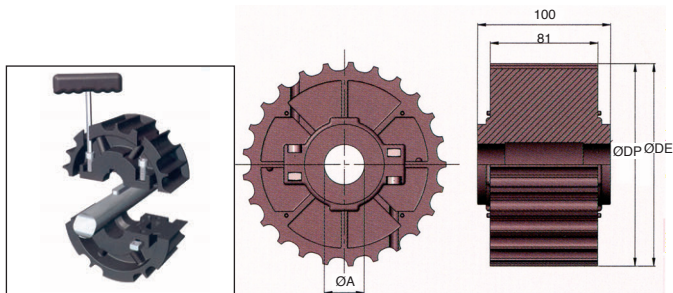

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



UGH25

H Type Guide units,
For Ø25 actuators




PCS375S

Chain sprocket -
Stainless steel, 9.525
(DIN 06B-1)



CTZYSS

 Stainless steel diabolo
shaped elasto mount,
Stainless steel



PRF4545r90

Standard aluminium
profile, 45 x 45 mm -
R90°



YG2

HEAVY DUTY spur
gear, Steel 35NCD6



CCL5S

Stainless steel wire
thimble, Stainless
steel



HAS

Captive C washer,
Slotted flat headed
shoulder screw



BOX-CS

Hose clamp, Box set
of steel hose clamps



MEB

Moulded plastic bevel
gear (nylon), 1:1



PTA80

Articulated levelling
foot, pressed base
Ø80, Ø 80



EML

Stainless steel
hexagonal headed
thumb nut, Lobed



BPQ

Quadro linear ball
bearing unit, Included
4 linear ball bearings

Complementary products