



Idler sprocket for plate chain

For chain ranges 821 and 805



PR821

- For use with CAP821 and CAP805 plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Easy assembly

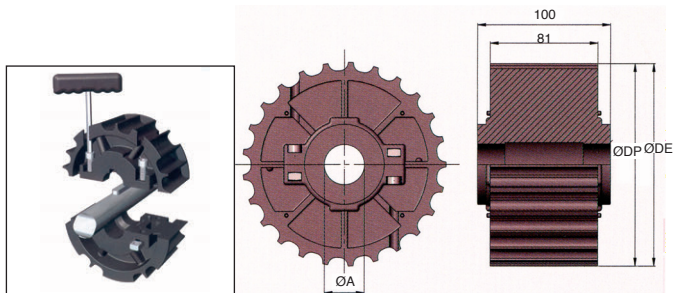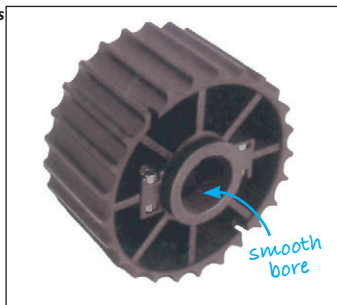

Two part design

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR821-25-30	25	153	153,2	30	0,9	70,12 €
PR821-25-35	25	153	153,2	35	0,9	70,12 €
PR821-25-40	25	153	153,2	40	0,9	70,12 €
PR821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Our other products



U8R

Bellows cover, Low cost



TFR

Tensioner plate, Fixed



ALIDRP240

Power supply, 10 A



BOX-TOR-TOOL

Box set of Nitrile O-rings, Extraction tools



MFB_MHB

Moulded plastic bevel gear (nylon), 1.5:1



WING

Manually tightened wing nut, Steel (ANSI B18-17)



PSG2S

Spur gear - precision range, Stainless steel 316



CNA-CNG

Gas spring, Right angled mounting plate for clevis



GPLss

Brush, stainless steel



CLASS

Clamping lever - female, Stainless steel



CDR

Ball pin, Retaining cable



DOG319

DC Motor and gearbox combination, from 4 to 9 Nm

Complementary products