

- **Levelling foot**
- Non slip base
- Materials:
  - Base: Black glass reinforced polyamide (Shore 70)
  - Spindle: Zinc plated steel or stainless 304 steel
- Supplied without nut



### Advantages

- Articulated rod allows auto-alignment with the ground
- Sole material ensures flexibility and grip

### Info.

- Values given for static, should will be reduced in case of a vibrating load

**With non-slip base**

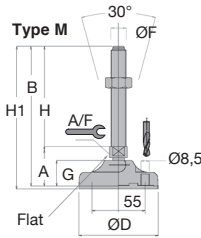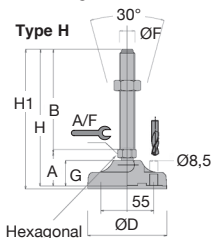

### DISCOUNTS

Qty	1+	20+	50+
Disc.	List -10%	On request	

Part number	ØD	Thread		B	A	A/F	G	H	H1	Static load (N)	Type	Price each
		ØF	B									
<b>Steel spindle</b>												
PR85-12-75	83	M12	75	38	14	27	113	116	15000	H	✓	10,59 €
PR85-12-125	83	M12	125	38	14	27	163	166	15000	H	✓	11,83 €
PR85-16-75	83	M16	75	38	16	27	113	116	20000	H	✓	11,14 €
PR85-16-150	83	M16	150	38	16	27	188	191	20000	H	✓	13,10 €
PR85-16-200	83	M16	200	38	16	27	238	241	20000	H	✓	14,43 €
PR85-20-125	83	M20	125	41	17	27	166	169	20000	M	✓	12,13 €
PR85-20-175	83	M20	175	41	17	27	216	219	20000	M	✓	13,86 €
PR85-20-225	83	M20	225	41	17	27	266	269	20000	M	✓	15,75 €
<b>Stainless steel spindle</b>												
PR85-12-75/SS	83	M12	75	38	14	27	113	116	15000	H	✓	17,99 €
PR85-12-125/SS	83	M12	125	38	14	27	163	166	15000	H	✓	20,70 €
PR85-16-75/SS	83	M16	75	41	13	27	116	119	20000	M	✓	17,99 €
PR85-16-150/SS	83	M16	150	41	13	27	191	194	20000	M	✓	22,05 €
PR85-16-200/SS	83	M16	200	41	13	27	241	244	20000	M	✓	24,79 €
PR85-20-125/SS	83	M20	125	41	17	27	166	169	20000	M	✓	25,21 €
PR85-20-175/SS	83	M20	175	41	17	27	216	219	20000	M	✓	29,70 €
PR85-20-225/SS	83	M20	225	41	17	27	266	269	20000	M	✓	35,90 €

\*Depending on availability - Dimensions in mm

## Our other products



BLHT50  
Right angled gearbox,  
from 11.50 to 30 Nm



BAG0  
Locking rings in  
stainless steel,  
Stainless steel



PSG15  
Spur gear - precision  
range, Stainless steel  
303



PRF\_PGN  
Door handle for  
aluminium profile,  
Handle with lock  
suitable



PTA80  
Articulated levelling  
foot, pressed base  
Ø80, Ø 80



DTR  
Chain idler sprocket,  
Chain idler sprocket -  
Plastic



RVM14  
Manual worm and  
wheel gearbox,  
Worm/wheel



HK  
Manual locking clamp,  
Manual locking clamp  
LWH



ZBconique  
Machined plastic  
bevel gear , 1:1



LACT\_SS  
Adjustable Stainless  
steel cam lever, Male



BTC\_M  
End cap with threaded  
insert for square tube,



PLN  
Cylindrical spacer,  
Thermoplastic

## Complementary products



ESCB  
Combined bipod  
support base, Bipod  
support element with  
cross support



ESSB  
Bipod support base,  
Bipod support base