

Idler sprocket for plate chain



PR880


For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

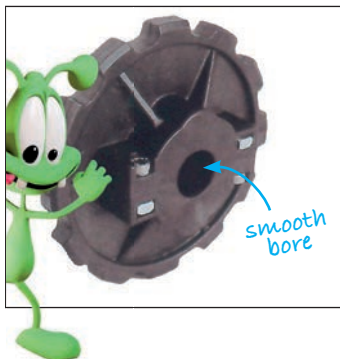

Two part design

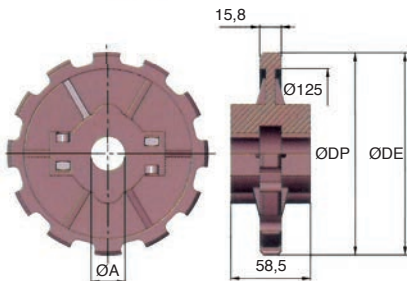

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	27,32 €
PR880-12-30	12	147,2	147,21	30	0,39	27,32 €
PR880-12-35	12	147,2	147,21	35	0,39	27,32 €
PR880-12-40	12	147,2	147,21	40	0,39	27,32 €

Dimensions in mm

Our other products



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



WJUM20

Drylin® W bearing block, Slide



RTE

Rotex®, jaw coupling, cast iron



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



SLB

Indexing plunger, stainless steel



CLG2-ALI

Spur gear for food industry, Moulded blue plastic (nylon)



T39_T49

Extension spring in metre length steel, by the metre



RDS

Safety washer Hygienic Usit®, Stainless steel



OP9

Mechanical digital position indicator, 5 numbers



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120 with counter and han...



BABS303

303 Stainless steel compact ball pin, Stainless steel 303



COA-COG

Surface mounting plate, Surface mounting plate for clevis

Complementary products



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



PT880

Drive sprocket for slat top chain, Range 880



BAP25

Plastic clamping collar, Ø25 - Ø40



BAP

Plastic clamping collar, Ø10 - Ø20