

Idler sprocket for plate chain



PR880


For chain range 880 TAB

- For use with CAP880T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

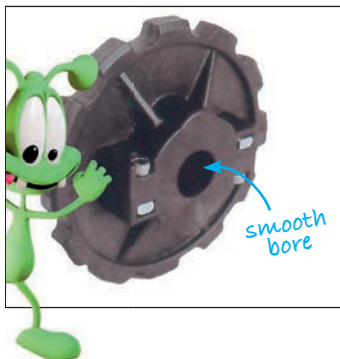

Two part design

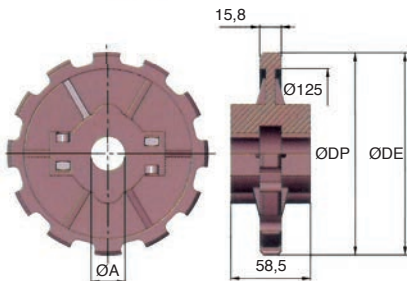

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR880-12-25	12	147,2	147,21	25	0,39	27,32 €
PR880-12-30	12	147,2	147,21	30	0,39	27,32 €
PR880-12-35	12	147,2	147,21	35	0,39	27,32 €
PR880-12-40	12	147,2	147,21	40	0,39	27,32 €

Dimensions in mm

Our other products



SHS

Shoulder screw
stainless steel 303,
Stainless steel 303



 
E20

Right angle helical
reducers, from 0.60 to
3.84 Nm



RJA10_03

Sealing strip, Clipping



PM3

Worm and wheel set,
Machined plastic
(delrin)



MRA_SS

Stainless steel Quick
link, Stainless steel



HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Steel



CHMX_CHMDX

Shaft for worm and
wheel reducer CHMR
and CHM, CHMR and
CHM gearbox...



CHM110

Worm and wheel gear
reducer, up to 980
Nm



UGAC_UGET

Connection for
threaded actuator
rod, Connection for



HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



PCS37K

Chain sprocket with
hardened teeth,
9.525mm (DIN06B-1)



DOG111

Motor-gearbox 12V
and 24V DC, from 1.5
to 6 Nm

Complementary products



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880



PT880

Drive sprocket for slat
top chain, Range 880



BAP25

Plastic clamping
collar, Ø25 - Ø40



BAP

Plastic clamping
collar, Ø10 - Ø20