

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

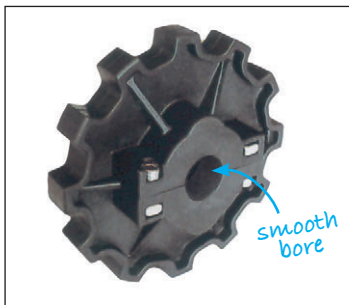

Two part design

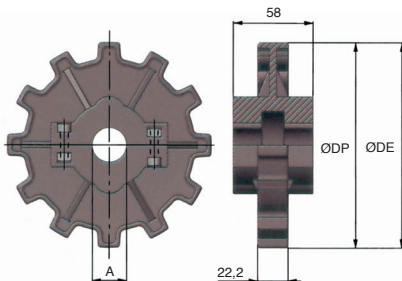

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



 
BPPL

Assembly tool for carrier ball, Mounting tool



EMAS

Antistatic knurled nut, Antistatic



M0

Worm and wheel set, Machined plastic (delrin)



NSA

Adjustable clamp, Articulated



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Steel



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions



SH0

Parallel axis helical gear, Machined plastic (delrin)



CLB_T

Die cast zinc clamping lever - male, Zamak



PPG

Indexing plunger with flange, With horizontal mounting



GLT3-46

Telescopic drawer,



CLG2

Moulded plastic spur gear, Moulded plastic (nylon)



ASM

Cylindrical polymer bush, Food grade polymer

Complementary products



CAP882

Flexible slat top chain acetal, Large range 882



PT882

Drive sprocket for slat top chain, Range 882