

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

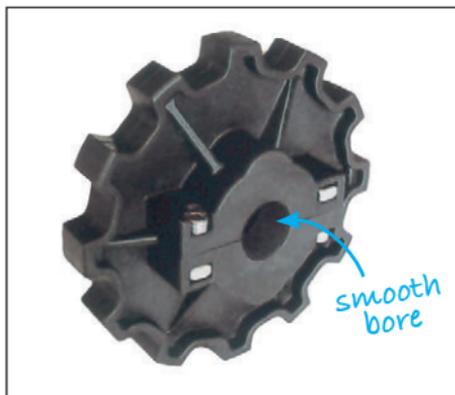

Two part design

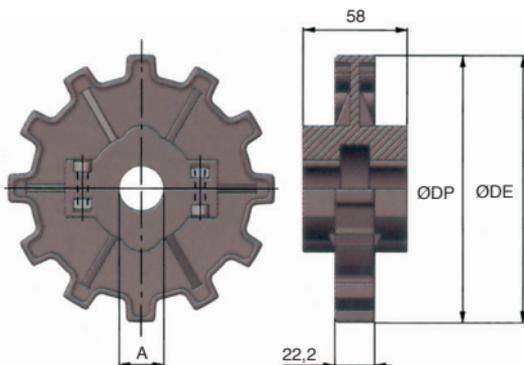

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €


Dimensions in mm

Our other products



PSG2

Spur gear - precision range, Case hardened steel 20NCD2

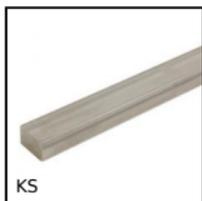

KS

Keysteel, Stainless steel - Keystock



CHARcav

Spring hinge, to install



ACLEPP

Right angled bracket for aluminium profile, 4 holes



HLUMss

Revolving handle for handwheel, Stainless steel 316



DILC

Indexing plunger with cam, with cam



SSB

Stainless steel bevel gear, 1:1




E60B

Right angle helical reducers, from 4.50 to 24 Nm




RPCpl

Swivel castor with double brake, Steel - Polyamide

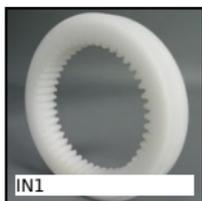

IN1

Internal gear, Machined plastic (delrin)

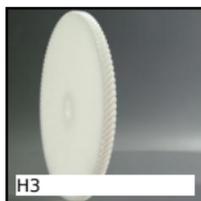

H3

Crossed helical gear crossed axis at 90°, Machined plastic



ACLCHARJ

Hinge for aluminium profile, Adjusts in 2 directions

Complementary products



CAP882

Flexible slat top chain acetal, Large range 882



PT882

Drive sprocket for slat top chain, Range 882