

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

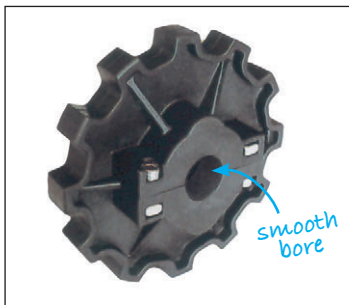

Two part design

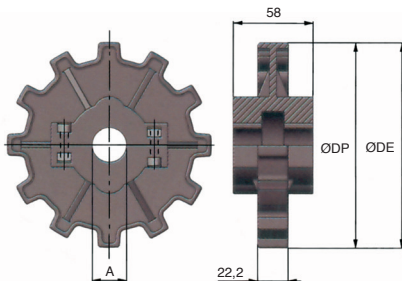

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



GE_ES_2R5

Spherical bushing,
Steel / steel with seals



BPHT

Ball transfer unit bolt
fitting, Heavy




PR105

Articulated foot $\varnothing 103$,
 $\varnothing 103$



PRF_PF

 Anchoring bracket for
aluminium profile,
Anchor



G0

Steel spur gear, Steel
20NC2



DOMI30

Domino 30 adjustable
slide, Slide DOMILINE
30 with counter and
handw...



PRF_BR

Clamp for aluminium
profile, Clamp for
profile



CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm




METC

Flanged sintered
bronze bush, Self-



UGH25

 H Type Guide units,
For $\varnothing 25$ actuators



AC

Strike for toggle latch,
15mm



SHTP

Drylin® Linear table,
Economy range

Complementary products



CAP882

Flexible slat top chain
acetal, Large range
882



PT882

Drive sprocket for slat
top chain, Range 882