

Idler sprocket for plate chain



PR882


For chain range 882 TAB

- For use with CAP882T plate chains
- Materials:
Reinforced polyamide
Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

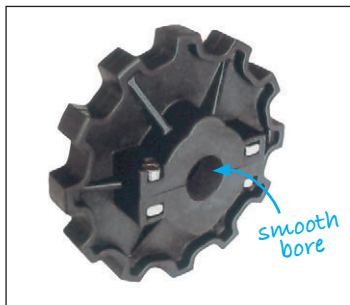

Two part design

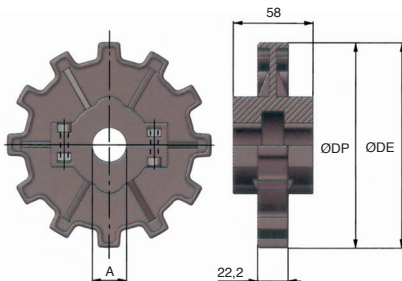

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PR882-12-25	12	148,5	147,2	25	0,38	29,36 €
PR882-12-30	12	148,5	147,2	30	0,38	29,36 €
PR882-12-35	12	148,5	147,2	35	0,38	29,36 €
PR882-12-40	12	148,5	147,2	40	0,38	29,36 €
PR882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Our other products



SHA_PTR

Handwheel with folding handle, Polyamide



BPTR_M

End cap with threaded insert for round tube, With threaded insert




INS_SS

Self tapping stainless steel insert, 316 stainless steel




G0

Steel spur gear, Steel 20NCD2

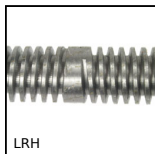


LRH

Bi-directional leadscrew, Bi-directional - 1 thread

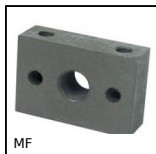

MF

Shock Absorber - universal flange, Universal fixing

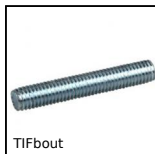

TIFbout

Threaded stud - DIN976A, Steel



ZBconique

Machined plastic bevel gear, 1:1



EKONSL

Silicone conical elasto buffer, Female mounting



HK

Manual locking clamp, Manual locking clamp LWL



WJUM16

Drylin® W bearing block, Slide



BPTRW

Cap for round tube to be welded, To be welded

Complementary products



CAP882

Flexible slat top chain acetal, Large range 882



PT882

Drive sprocket for slat top chain, Range 882